



Product data sheet

Specifications

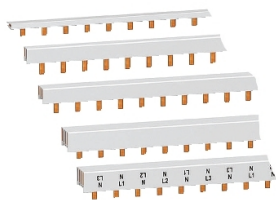

comb busbar Domae - 2 poles - 80
A - L = 54 x 18 mm

14802

 **Discontinued on:** Nov 22, 2017

 **Discontinued**

Main

Range Of Product	Domae
Product Or Component Type	Comb busbar
Accessory / Separate Part Category	Connection accessory
Poles Description	2P
Number Of Ways	27 ways 2 L 0.71 in (18 mm)
Distance Between Way	1.42 in (36 mm)
Length In 18 Mm Modules	54

Complementary

Line Rated Current	Double feed 100 A 104 °F (40 °C)) Single feed 80 A 104 °F (40 °C))
[Ui] Rated Insulation Voltage	500 V IEC 60664
Mounting Mode	Horizontal
9 Mm Pitches	108
Width	39.37 in (1000 mm)

Ordering and shipping details

Category	00908-C60N SUPPLEMENTARY PROTECTORS
Discount Schedule	DE2
Gtin	00785901797395
Returnability	No
Country Of Origin	FR

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	0.79 in (2 cm)
Package 1 Width	3.15 in (8 cm)
Package 1 Length	39.37 in (100 cm)
Package 1 Weight	0.09 lb(US) (0.04 kg)

Contractual warranty

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Warranty

18 months