


Product data sheet

Specifications

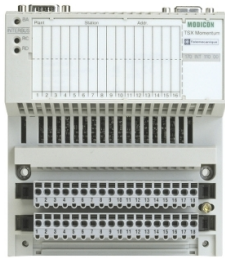

Modicon Momentum - Conformal coating - Interbus communication adaptor

170INT11003C

! Discontinued

! Discontinued on: Apr 29, 2022

! End-of-service on: Dec 31, 2023

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

Range Of Product	Modicon Momentum automation platform
Product Or Component Type	Interbus communication adaptor
Communication Port Protocol	Interbus generation SUP1 3
Method Of Access	Continuous shift register Master/slave
Transmission Rate	500 kbit/s
Transmission Support Medium	Twisted pair

Complementary

Topology	Ring
Number Of Devices Per Segment	0...254
Maximum Cable Distance Between Devices	41994.75 ft (12800 m) 1312.34 ft (400 m) between two modules
Fail State	Fail safe
Control Parameter	CRC-16
Supply	From I/O base
Marking	CE
Local Signalling	for bus enable (BA) 1 LED for remote bus check (RC) 1 LED for remote bus disabled (RD) 1 LED for logic power check (UL) 1 LED
Electrical Connection	2 connectors SUB-D 9 for connecting Interbus
Module Format	Standard
Net Weight	0.15 lb(US) (0.07 kg)

Environment

Product Certifications	CSA UL FM Class 1 Division 2
Ip Degree Of Protection	IP20
Protective Treatment	TC Conformal coating Humiseal 1A33

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Resistance To Electrostatic Discharge	4 kV contact IEC 801-2 8 kV on air IEC 801-2
Resistance To Electromagnetic Fields	9.14 V/m (10 V/m) 80...1000 MHz IEC 801-3
Ambient Air Temperature For Operation	32...140 °F (0...60 °C)
Ambient Air Temperature For Storage	-40...185 °F (-40...85 °C)
Relative Humidity	95 % without condensation
Operating Altitude	<= 16404.2 ft (5000 m)

Ordering and shipping details

Category	US1PC3118206
Discount Schedule	PC31
Gtin	3595863798821
Returnability	No
Country Of Origin	FR

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.17 in (5.5 cm)
Package 1 Width	7.09 in (18.0 cm)
Package 1 Length	10.24 in (26.0 cm)
Package 1 Weight	7.55 oz (214.0 g)
Unit Type Of Package 2	S02
Number Of Units In Package 2	2
Package 2 Height	5.91 in (15.0 cm)
Package 2 Width	11.81 in (30.0 cm)
Package 2 Length	15.75 in (40.0 cm)
Package 2 Weight	15.10 oz (428.0 g)

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability

Green Premium™ label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

Well-being performance



Mercury Free



Rohs Exemption Information

Yes

Reach Regulation

[REACH Declaration](#)

Eu Rohs Directive

Pro-active compliance (Product out of EU RoHS legal scope)

China Rohs Regulation

[China RoHS declaration](#)

Weee

The product must be disposed on European Union markets following specific waste collection and never end up in rubbish bins.

California Proposition 65

WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov