


# Product data sheet

Specifications

SQUARE D

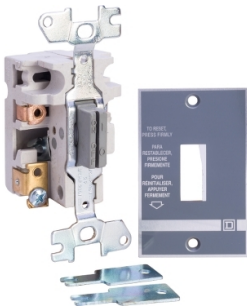

## FHP Manual Starter - Open - 1P - Key Operated - No Indicator - 277VAC

2510FO3

Discontinued on: Jun 30, 2020

Discontinued

Product availability: Non-Stock - Not normally stocked in distribution facility

### Main

|                     |                            |
|---------------------|----------------------------|
| Product             | Single Unit Manual Starter |
| Type                | F                          |
| Overload Relay Type | Melting alloy              |

### Complementary

|                       |                                                 |
|-----------------------|-------------------------------------------------|
| Current Rating        | 16 A                                            |
| Cable Entry           | Without                                         |
| Horsepower Rating     | 1 hp 115 V AC<br>1 hp 230 V AC<br>1 hp 277 V AC |
| Voltage Rating        | 277 V AC                                        |
| Number Of Poles       | 1P                                              |
| Control Unit          | Key                                             |
| Number Of Phases      | 1 phase                                         |
| Pilot Light           | No indicator                                    |
| Reset                 | Manual                                          |
| Motor Starter Type    | Non reversing                                   |
| Electrical Connection | Screw clamp terminals                           |
| Wire Gauge            | AWG 14...AWG 12 copper                          |
| Height                | 4.13 in (104.90 mm)                             |
| Width                 | 1.69 in (42.93 mm)                              |
| Depth                 | 2.22 in (56.39 mm)                              |

### Environment

|                        |                                                             |
|------------------------|-------------------------------------------------------------|
| Product Certifications | UL recognized E42243 CCN NLRV2<br>CSA LR25490 class 3211 05 |
| Nema Enclosure Rating  | Not rated (open device)                                     |

### Ordering and shipping details

|                   |                |
|-------------------|----------------|
| Category          | US10CP121101   |
| Discount Schedule | OCP1           |
| Gtin              | 00785901554172 |

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

|                   |    |
|-------------------|----|
| Returnability     | No |
| Country Of Origin | MX |

### Packing Units

|                              |     |
|------------------------------|-----|
| Unit Type Of Package 1       | PCE |
| Number Of Units In Package 1 | 1   |

### Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

## Well-being performance

 Reach Free Of Svhc

 Pvc Free

## Eu Rohs Directive

Not compliant

## China Rohs Regulation

### China RoHS declaration

Product out of China RoHS scope. Substance declaration for your information.

## California Proposition 65

WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)