


# 2510KF1AG

Manual Switch - Flush Mount - 2P - Toggle  
Operated - Green Indicator - 600VAC



Price\* : 137.60 USD

2510KF1AG has not been replaced. Please contact your customer care center for more information.

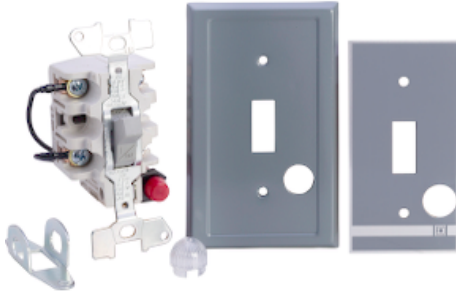

ⓘ Discontinued

## Main

Product	Single Unit Manual Switch
Type	K

## Complementary

Line Rated Current	30 A
Horsepower Rating	3 hp at 460 V AC 2 hp at 230 V AC 2 hp at 115 V AC 3 hp at 575 V AC 1 hp at 90 V DC 2 hp at 115 V DC 1.5 hp at 230 V DC
System Voltage	600 V AC 230 V DC
Number of Poles	2P
Control Unit Type	Toggle
Phase	1 phase
Pilot Light	Green indicator 115 V
Starter Type	Non reversing
Electrical Connection	Screw clamp terminals
Wire Gauge	AWG 14...AWG 10 (copper)
Height	4.25 in
Width	2.44 in
Depth	2.75 in

## Environment

Certifications	UL listed file E42243 CCN NLRV CSA LR25490 class 3211 05
NEMA Enclosure Rating	Not rated (flush plate) painted sheet steel standard size

## Ordering and shipping details

Category	21102 - 2510,2511,2512 K
Discount Schedule	CP1
Nbr. of units in pkg.	1
Package weight(Lbs)	0.5
Returnability	N
Country of origin	MX

## Offer Sustainability

RoHS (date code: YYWW)	Will be compliant Will be compliant
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold

## Contractual warranty

Warranty period	18 months
-----------------	-----------