


2510KF2BG

Manual Switch - Flush Mount - 3P - Toggle
Operated - Green Indicator - 600VAC



Price* : 225.93 USD

2510KF2BG has not been replaced. Please contact your customer care center for more information.

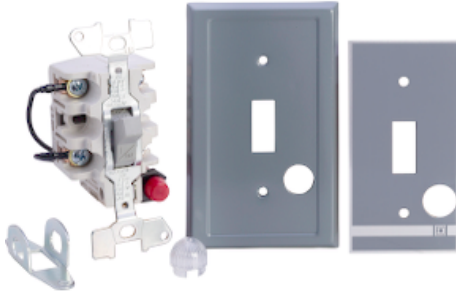

⚠ Discontinued

Main

Product	Single Unit Manual Switch
Type	K

Complementary

Line Rated Current	30 A
Horsepower Rating	2 hp at 115 V AC 1 hp at 90 V DC 2 hp at 115 V DC 1.5 hp at 230 V DC 7.5 hp at 230 V AC 10 hp at 460 V AC 10 hp at 575 V AC
System Voltage	600 V AC 230 V DC
Number of Poles	3P
Control Unit Type	Toggle
Phase	3 phases
Pilot Light	Green indicator 208...277 V
Starter Type	Non reversing
Electrical Connection	Screw clamp terminals
Wire Gauge	AWG 14...AWG 10 (copper)
Height	4.25 in
Width	2.44 in
Depth	2.75 in

Environment

Certifications	UL listed file E42243 CCN NLRV CSA LR25490 class 3211 05
NEMA Enclosure Rating	Not rated (flush plate) painted sheet steel standard size

Ordering and shipping details

Category	21102 - 2510,2511,2512 K
Discount Schedule	CP1
Nbr. of units in pkg.	1
Package weight(Lbs)	0.5
Returnability	N
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Will be compliant on 3Q2014 Will be compliant on 3Q2014
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold

Contractual warranty

Warranty period	18 months
-----------------	-----------