

Product data sheet

Characteristics


2510KO1BT

Replacment Manual Switch - Open - 2P - Toggle
Operated - Red Indicator - 600VAC

Product availability : Non-Stock - Not normally stocked in distribution facility



Price* : 145.05 USD

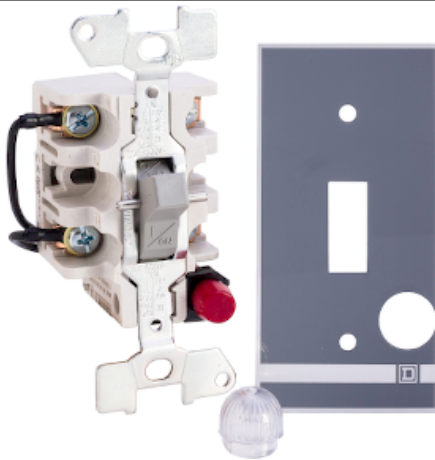

Main

Product	Single Unit Manual Switch
Type	K

Complementary

Line Rated Current	30 A
Horsepower Rating	3 hp at 460 V AC 2 hp at 230 V AC 2 hp at 115 V AC 3 hp at 575 V AC 1 hp at 90 V DC 2 hp at 115 V DC 1.5 hp at 230 V DC
System Voltage	600 V AC 230 V DC
Number of Poles	2P
Control Unit Type	Toggle
Phase	1 phase
Pilot Light	Red indicator 230 V
Starter Type	Non reversing
Electrical Connection	Screw clamp terminals
Wire Gauge	AWG 14...AWG 10 (copper)
Height	4.13 in
Width	1.69 in
Depth	2.34 in

Environment

Certifications	CE CSA LR25490 class 3211 05
----------------	---------------------------------

UL recognized E42243 CCN NLRV2

NEMA Enclosure Rating	Not rated (open device)
-----------------------	-------------------------

Ordering and shipping details

Category	21102 - 2510,2511,2512 K
Discount Schedule	CP1
Nbr. of units in pkg.	1
Package weight(Lbs)	0.87
Returnability	N
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Compliant Schneider Electric declaration of conformity
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------