

Product data sheet

Characteristics


2510KSJ2C

Manual Switch - Jumbo SS Flush - 3P - Toggle
Operated - Red Indicator - 600VAC

Product availability : Non-Stock - Not normally stocked in distribution facility



Price* : 250.30 USD

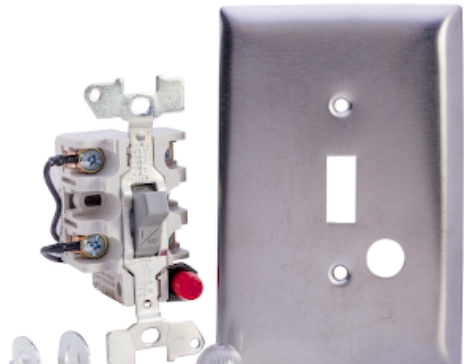

⚠ Discontinued

2510KSJ2C has not been replaced. Please contact your customer care center for more information.

Main

Product or component type	Single Unit Manual Switch
Range of product	K

Complementary

Line Rated Current	30 A
Motor power hp	2 hp at 115 V AC 1 hp at 90 V DC 2 hp at 115 V DC 1.5 hp at 230 V DC 7.5 hp at 230 V AC 10 hp at 460 V AC 10 hp at 575 V AC
System Voltage	600 V AC 230 V DC
Poles description	3P
Control type	Toggle
Phase	3 phases
Local signalling	Red indicator 440...600 V
Motor starter type	Non reversing
Electrical connection	Screw clamp terminals
AWG gauge	AWG 14...AWG 10 (copper)
Height	5.25 in
Width	3.5 in
Depth	2.5 in

Environment

Product certifications	CE UL listed file E42243 CCN NLRV CSA LR25490 class 3211 05
------------------------	---

NEMA degree of protection	Not rated (flush plate) stainless steel oversized
---------------------------	---

Ordering and shipping details

Category	21102 - 2510,2511,2512 K
Discount Schedule	CP1
GTIN	00785901342335
Nbr. of units in pkg.	1
Package weight(Lbs)	0.5
Returnability	N
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1545 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------