


2510KSJ3B

Manual Switch - Jumbo SS Flush - 2P - Key
Operated - Red Indicator - 600VAC

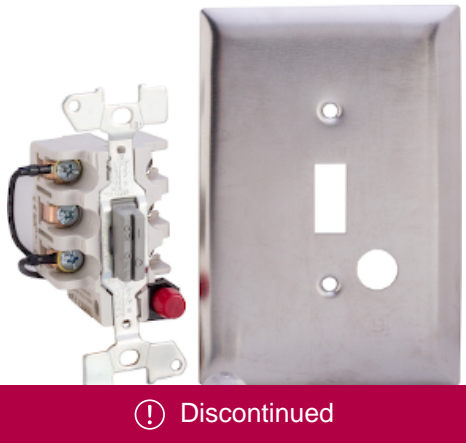

Price* : 194.36 USD



⚠ Discontinued

2510KSJ3B has not been replaced. Please contact your customer care center for more information.

Main

Product	Single Unit Manual Switch
Type	K

Complementary

Line Rated Current	30 A
Horsepower Rating	3 hp at 460 V AC 2 hp at 230 V AC 2 hp at 115 V AC 3 hp at 575 V AC 1 hp at 90 V DC 2 hp at 115 V DC 1.5 hp at 230 V DC
System Voltage	600 V AC 230 V DC
Number of Poles	2P
Control Unit Type	Key
Phase	1 phase
Pilot Light	Red indicator 230 V
Starter Type	Non reversing
Electrical Connection	Screw clamp terminals
Wire Gauge	AWG 14...AWG 10 (copper)
Height	5.25 in
Width	3.5 in
Depth	2.5 in

Environment

Certifications	CE UL listed file E42243 CCN NLRV CSA LR25490 class 3211 05
----------------	---

NEMA Enclosure Rating	Not rated (flush plate) stainless steel oversized
-----------------------	---

Ordering and shipping details

Category	21102 - 2510,2511,2512 K
Discount Schedule	CP1
Nbr. of units in pkg.	1
Package weight(Lbs)	0.5
Returnability	N
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Will be compliant on 3Q2014 Will be compliant on 3Q2014
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold

Contractual warranty

Warranty period	18 months
-----------------	-----------