


Product availability : Stock - Normally stocked in distribution facility



Price* : 390.00 USD

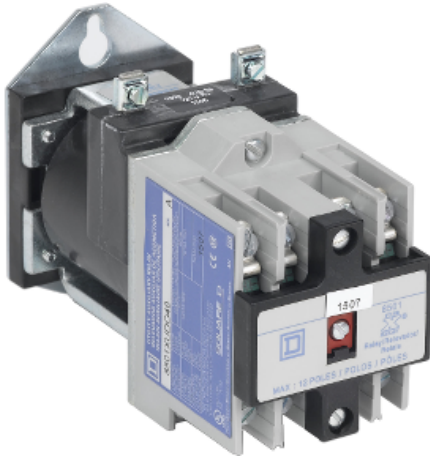

Main

Range	8501X
Relay Type	Utility
Product	Relay
Current Rating	10 A AC 5 A DC
Contact Configuration	4 NO 4 standard contact cartridges
Number of Poles	4P
Coil Voltage	125 V DC
Voltage Rating	250 V DC
Mounting Type	Panel
Operating Temperature	-40...160 °F
Electrical Connection	Screw clamp terminals
Certifications	CE CSA UL listed
Operating Time	37 ms pick-up 21 ms drop-out

Ordering and shipping details

Category	21157 - 8501 XDO (DC)
Discount Schedule	CP2
GTIN	00785901743316
Nbr. of units in pkg.	1
Package weight(Lbs)	3.2600000000000002
Returnability	Y
Country of origin	MX

Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 1332 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold
Product environmental profile	Available
Product end of life instructions	Available
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------