


8502SCO1V01

Non-Reversing Contactor, Size 1, 2-Pole, Open Style

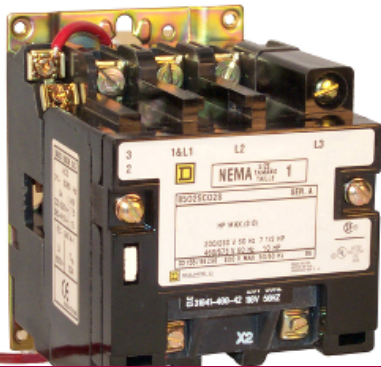

Price* : 441.00 USD



⚠ Discontinued

8502SCO1V01 has not been replaced. Please contact your customer care center for more information.

Main

Product or component type	Contactors
Type	8502S
Control Circuit Type	Common control circuit
Control Circuit Voltage	24 V AC 60 Hz
Contactor Type	Non-reversing
Line Rated Current	27 A
Number of Poles	2P
Phase	1 phase
Horsepower Rating	3 HP 230 V AC 2 HP 115 V AC
System Voltage	600 V AC
Control Units	No control units
Pilot Light	No indicator
Auxiliary Contacts	Without
Control Circuit Fusing	Fuse not supplied
Electrical connection	Screw clamp terminals
Enclosure Type	Not rated (open device)
Product certifications	UL listed CSA
NEMA size	1

Ordering and shipping details

Category	21192 - 8502,36 SC,SD(NOT S*R,T,W)
Discount Schedule	CP1
Nbr. of units in pkg.	1
Package weight(Lbs)	4
Returnability	N
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Will be compliant Will be compliant
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold

Contractual warranty

Warranty period	18 months
-----------------	-----------
