


# 8502SCO1V02

## Non-Reversing Contactor, Size 1, 2-Pole, Open Style

Product availability : Non-Stock - Not normally stocked in distribution facility



Price\* : 441.00 USD

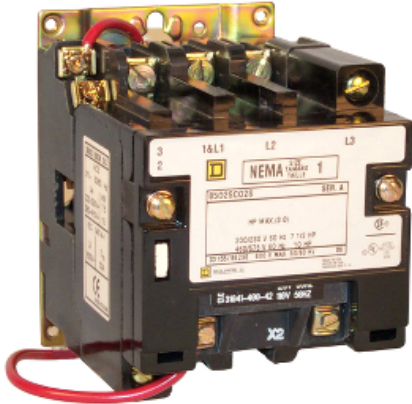

### Main

Product or component type	Contacteur
Type	8502S
Control Circuit Type	Common control circuit
Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Contacteur Type	Non-reversing
Line Rated Current	27 A
Number of Poles	2P
Phase	1 phase
Horsepower Rating	3 HP 230 V AC 2 HP 115 V AC
System Voltage	600 V AC
Control Units	No control units
Pilot Light	No indicator
Auxiliary Contacts	Without
Control Circuit Fusing	Fuse not supplied
Electrical connection	Screw clamp terminals
Enclosure Type	Not rated (open device)
Product certifications	CSA UL listed
NEMA size	1
Height	4.33 in (110 mm)
Depth	4.21 in (107 mm)
Width	3.23 in (82 mm)

### Ordering and shipping details

Category 21192 - 8502,36 SC,SD(NOT S\*R,T,W)

Discount Schedule	CP1
GTIN	00785901018650
Nbr. of units in pkg.	1
Package weight(Lbs)	3.8500000000000001
Returnability	N
Country of origin	MX

**Offer Sustainability**

RoHS (date code: YYWW)	Compliant <a href="#">Schneider Electric declaration of conformity</a>
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

**Contractual warranty**

Warranty period	18 months
-----------------	-----------