

# Product data sheet

## Characteristics


# 8502SCO2V02S

Type S nonreversing magnetic contactor, NEMA Size 1, 3 P, 110/120 VAC 50/60 Hz coil, melting alloy overload, open

Product availability : Stock - Normally stocked in distribution facility



Price\* : 485.00 USD

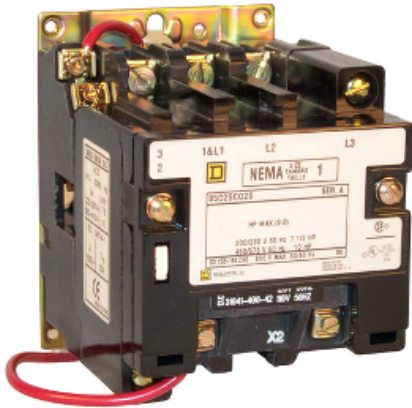

### Main

Product or component type	Contactor
Type	8502S
Control Circuit Type	Separate control circuit
Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Contactor Type	Non-reversing
Line Rated Current	27 A
Number of Poles	3P
Phase	3 phases
Horsepower Rating	7.5 HP 200 V AC 7.5 HP 230 V AC 10 HP 460 V AC 10 HP 575 V AC
System Voltage	600 V AC
Control Units	No control units
Pilot Light	No indicator
Auxiliary Contacts	Without
Control Circuit Fusing	Fuse not supplied
Electrical connection	Screw clamp terminals
Enclosure Type	Not rated (open device)
Product certifications	UL listed CSA
NEMA size	1
Height	4.33 in (110 mm)
Depth	4.21 in (107 mm)
Width	3.23 in (82 mm)

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

**Ordering and shipping details**

Category	21192 - 8502,36 SC,SD(NOT S*R,T,W)
Discount Schedule	CP1
GTIN	00785901862901
Nbr. of units in pkg.	1
Package weight(Lbs)	3.3000000000000003
Returnability	Y
Country of origin	MX

**Offer Sustainability**

RoHS (date code: YYWW)	Compliant <a href="#">Schneider Electric declaration of conformity</a>
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

**Contractual warranty**

Warranty period	18 months
-----------------	-----------