


8502SHO2V02S

Non-Reversing Contactor, Size 6, 3-Pole, Open Style +Options

Product availability : Non-Stock - Not normally stocked in distribution facility



Price* : 20,339.00 USD

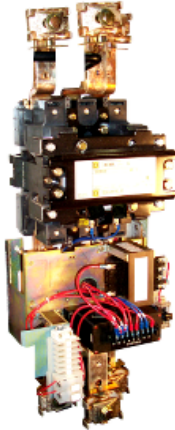

Main

Product or component type	Contacteur
Type	8502S
Control Circuit Type	Control circuit transformer
Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Contacteur Type	Non-reversing
Line Rated Current	540 A
Number of Poles	3P
Phase	3 phases
Horsepower Rating	150 HP 200 V AC 200 HP 230 V AC 400 HP 460 V AC 400 HP 575 V AC
System Voltage	600 V AC
Control Units	No control units
Pilot Light	No indicator
Auxiliary Contacts	Without
Control Circuit Fusing	2 fuses (primary)
Electrical connection	Screw clamp terminals
Enclosure Type	Not rated (open device)
Product certifications	CSA UL listed
NEMA size	6
Height	713 mm
Depth	9.02 in (229 mm)
Width	12.32 in (313 mm)

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications.

Ordering and shipping details

Category	21195 - 8502,36 SH,SJ(NOT S*R,T,W)
Discount Schedule	CP1
GTIN	00785901152354
Nbr. of units in pkg.	1
Package weight(Lbs)	74.87999999999995
Returnability	Y
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1545 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------