


8536SAO11V02ES

Non-Reversing Starter Size 00, 2-Pole, Bi-Metallic Overload, Open +Options

Product availability : Non-Stock - Not normally stocked in distribution facility

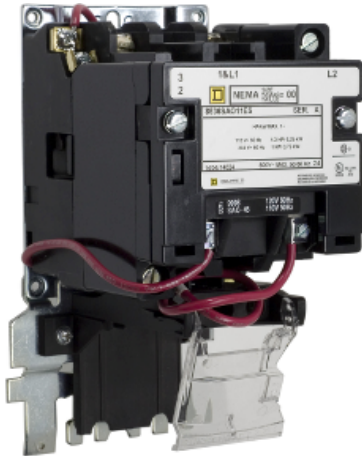

Main

Product or component type	Starter
Type	S
Control Circuit Type	Separate control circuit

Complementary

Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Motor starter type	Non reversing
Line Rated Current	9 A
Number of Poles	2P
Phase	1 phase
Horsepower Rating	0.33 HP 115 V AC 1 HP 230 V AC
System Voltage	600 V AC
Control Units	No control units
Thermal overload type	Non-compensated bimetallic 1 Thermal Units
Electrical connection	Screw clamp terminals
NEMA size	00
Height	6.77 in (172 mm)
Depth	4.21 in (107 mm)
Width	3.5 in (89 mm)

Environment

Enclosure Type	Not rated (open device)
Product certifications	CSA NEMA UL listed

Ordering and shipping details

Category	21191 - 8502,36 SA,SB(NOT S*R,T,W)
Discount Schedule	CP1
GTIN	00785901145240
Nbr. of units in pkg.	1
Package weight(Lbs)	3.3599999999999999
Returnability	Y
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1545 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to www.p65warnings.ca.gov