

# Product data sheet

## Characteristics


# 8536SCO1V02SX11

## Non-Reversing Starter Size 1, 2-Pole, Melting Alloy Overload +Options

Product availability : Non-Stock - Not normally stocked in distribution facility



Price\*\* : 822.00 USD

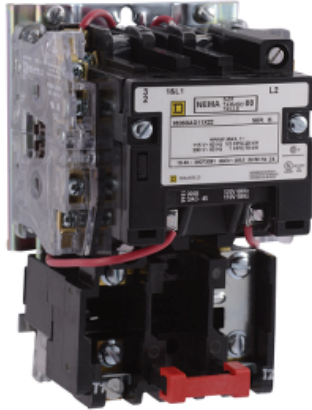

### Main

Product or component type	Starter
Type	S
Control Circuit Type	Separate control circuit

### Complementary

Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Motor starter type	Non reversing
Line Rated Current	27 A
Number of Poles	2P
Phase	1 phase
Horsepower Rating	3 HP 230 V AC 2 HP 115 V AC
System Voltage	600 V AC
Control Units	No control units
Auxiliary Contacts	1 NO + 1 NC
Thermal overload type	Melting alloy 1 Thermal Units
Electrical connection	Screw clamp terminals
NEMA size	1
Height	6.77 in (172 mm)
Depth	4.21 in (107 mm)
Width	4.02 in (102 mm)

### Environment

Enclosure Type	Not rated (open device)
Product certifications	CSA

NEMA  
UL listed

---

### Ordering and shipping details

Category	21192 - 8502,36 SC,SD(NOT S*R,T,W)
Discount Schedule	CP1
Nbr. of units in pkg.	1
Package weight(Lbs)	5
Returnability	N
Country of origin	MX

### Offer Sustainability

RoHS (date code: YYWW)	Will not be compliant <a href="#">Will not be compliant</a>
California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
- - - - - More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

### Contractual warranty

Warranty period	18 months
-----------------	-----------