


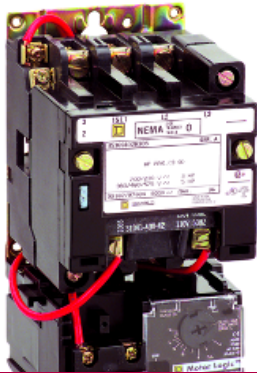

Price\* : 620.00 USD



ⓘ Discontinued

### Main

Product or component type	Starter
Type	S
Control Circuit Type	Separate control circuit

### Complementary

Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Motor starter type	Non reversing
Line Rated Current	27 A
Number of Poles	3P
Phase	3 phases
Horsepower Rating	7.5 HP 200 V AC 7.5 HP 230 V AC 10 HP 460 V AC 10 HP 575 V AC
System Voltage	600 V AC
Control Units	No control units
Thermal overload type	Solid state Motor Logic class 20
Electrical connection	Screw clamp terminals
NEMA size	1

### Environment

Enclosure Type	Not rated (open device)
Product certifications	CSA NEMA UL listed

## Ordering and shipping details

Category	21192 - 8502,36 SC,SD(NOT S*R,T,W)
Discount Schedule	CP1
GTIN	00785901070818
Nbr. of units in pkg.	1
Package weight(Lbs)	4.1600000000000001
Returnability	N
Country of origin	MX

## Offer Sustainability

RoHS (date code: YYWW)	Will be compliant Will be compliant
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold

## Contractual warranty

Warranty period	18 months
-----------------	-----------

## 8536SCO3V02H20S is replaced by:



### 8536S Non-Reversing Starter 8536SCO3V02H30S

Type S nonreversing magnetic starter, NEMA Size 1, 4 P, 110/120 VAC 50/60 Hz coil, Motor Logic overload, open

Qty 1

Reason for Substitution: End of life | Substitution date: 01 January 2017