

# Product data sheet

## Characteristics


# 8536SCO3V02H30S

Type S nonreversing magnetic starter, NEMA Size 1, 4 P, 110/120 VAC 50/60 Hz coil, Motor Logic overload, open

Product availability : Stock - Normally stocked in distribution facility



Price\* : 650.00 USD

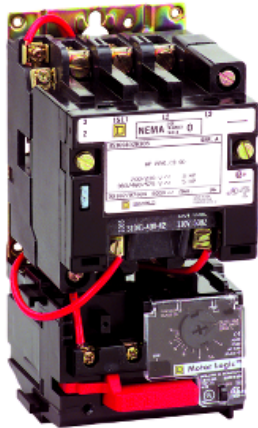

### Main

Product or component type	Starter
Type	S
Control Circuit Type	Separate control circuit

### Complementary

Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Motor starter type	Non reversing
Line Rated Current	27 A
Number of Poles	3P
Phase	3 phases
Horsepower Rating	7.5 HP 200 V AC 7.5 HP 230 V AC 10 HP 460 V AC 10 HP 575 V AC
System Voltage	600 V AC
Control Units	No control units
Thermal overload type	Solid state Motor Logic class 10/20
Electrical connection	Screw clamp terminals
NEMA size	1
Height	6.77 in (172 mm)
Depth	4.21 in (107 mm)
Width	3.5 in (89 mm)

## Environment

Enclosure Type	Not rated (open device)
Product certifications	CSA NEMA UL listed

## Ordering and shipping details

Category	21192 - 8502,36 SC,SD(NOT S*R,T,W)
Discount Schedule	CP1
GTIN	00785901807056
Nbr. of units in pkg.	1
Package weight(Lbs)	4
Returnability	Y
Country of origin	MX

## Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 1545 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

## Contractual warranty

Warranty period	18 months
-----------------	-----------