

Product data sheet

Characteristics


8536SCO3V02H318S

Non-Reversing Starter Size 1, 3-Pole, Motor Logic SSOLR, Open +Options

Product availability : Non-Stock - Not normally stocked in distribution facility



Price* : 705.50 USD

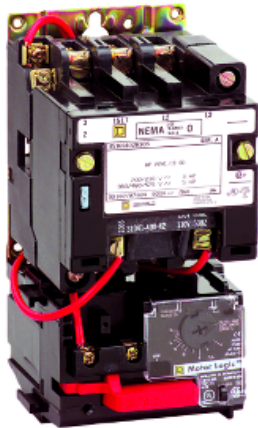

Main

Product or component type	Starter
Type	S
Control Circuit Type	Separate control circuit

Complementary

Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Motor starter type	Non reversing
Line Rated Current	27 A
Number of Poles	3P
Phase	3 phases
Horsepower Rating	7.5 HP 200 V AC 7.5 HP 230 V AC 10 HP 460 V AC 10 HP 575 V AC
System Voltage	600 V AC
Control Units	No control units
Thermal overload type	Solid state Motor Logic class 10/20
Electrical connection	Screw clamp terminals
NEMA size	1
Height	6.77 in (172 mm)
Depth	4.21 in (107 mm)
Width	3.5 in (89 mm)

Environment


Enclosure Type	Not rated (open device)
Product certifications	CSA

NEMA
UL listed

Ordering and shipping details

Category	21192 - 8502,36 SC,SD(NOT S*R,T,W)
Discount Schedule	CP1
GTIN	00785901815112
Nbr. of units in pkg.	1
Package weight(Lbs)	5
Returnability	N
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Compliant  Schneider Electric declaration of conformity
California proposition 65	WARNING: This product can expose you to chemicals including:
- - - - - Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
- - - - - More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------