

Product data sheet

Characteristics


8702SGO1V02S

Reversing Contactor, Size 5, 3-Pole, Vertical Open Style +Options

Product availability : Non-Stock - Not normally stocked in distribution facility



Price* : 16,592.00 USD

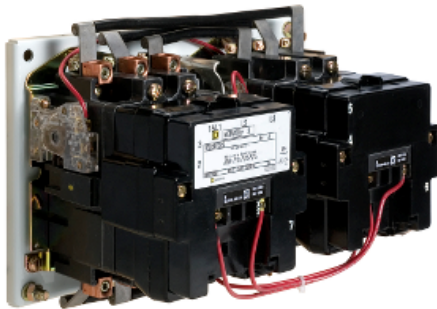

Main

Product	Contacteur
Type	Type S
Control Circuit Type	Separate control circuit

Complementary

Control Circuit Voltage	110 V AC 50 Hz 120 V AC 60 Hz
Contactor Type	Reversing
Number of Poles	3P
Phase	3 phases
Line Rated Current	270 A
Horsepower Rating	75 HP 200 V AC 100 HP 230 V AC 200 HP 460 V AC 200 HP 575 V AC
System Voltage	600 V AC
Control Units	No control units
Control Circuit Fusing	Fuse not supplied
Electrical connection	Screw clamp terminals
NEMA size	5
Height	874 mm
Depth	238 mm
Width	10.75 in (273 mm)

Environment

Enclosure Type	Not rated (open device)
Orientation	Vertical

Product certifications	CSA UL listed
------------------------	------------------

Ordering and shipping details

Category	21274 - 8702,36SG(NOT S*R,S*T,S*W)
Discount Schedule	CP1
Nbr. of units in pkg.	1
Package weight(Lbs)	127.76000000000001
Returnability	N
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Will not be compliant Will not be compliant
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------