

Product data sheet

Characteristics


8736SCO8V03

Reversing Starter Size 1, 3-Pole, Melting Alloy Overload

Product availability : Non-Stock - Not normally stocked in distribution facility



Price** : 1,241.00 USD

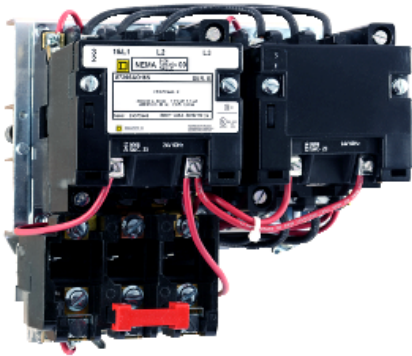

Main

Product	Starter
Type	S
Control Circuit Type	Common control circuit

Complementary

Control Circuit Voltage	220 V AC 50 Hz 240 V AC 60 Hz
Starter Type	Reversing
Number of Poles	3P
Phase	3 phases
Line Rated Current	27 A
Horsepower Rating	7.5 HP 200 V AC 7.5 HP 230 V AC 10 HP 460 V AC 10 HP 575 V AC
System Voltage	600 V AC
Control Units	No control units
Thermal overload type	Melting alloy 3 Thermal Units
Electrical connection	Screw clamp terminals
NEMA size	1
Height	6.93 in (176 mm)
Depth	5.31 in (135 mm)
Width	7.13 in (181 mm)

Environment

Enclosure Type	Not rated (open device)
Orientation	Horizontal

Product certifications	CSA NEMA UL listed
------------------------	--------------------------

Ordering and shipping details

Category	21272 - 8702,36 SC,SD(NOT S*R,T,W)
Discount Schedule	CP1
GTIN	00785901773108
Nbr. of units in pkg.	1
Package weight(Lbs)	7.6500000000000004
Returnability	N
Country of origin	MX

Offer Sustainability

RoHS (date code: YYWW)	Will not be compliant Will not be compliant
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to www.p65warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------