


Product data sheet

Specifications

SQUARE D

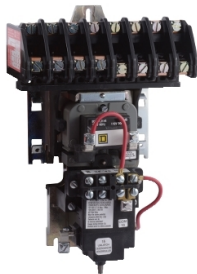

8903LX mechanically held lighting contactor, 8 P, 8 NO, 30 A, 600 V, 110/120 V 50/60 Hz coil, open

8903LXO80V02F4R6

⚠ Discontinued

Main

| | |
|---------------------------|--------------------------------------|
| Product Or Component Type | Mechanically Held Lighting Contactor |
| Range Of Product | 8903LX |
| Control Circuit | Separate control circuit |

Complementary

| | |
|------------------------|---|
| Control Voltage | 110 V AC 50 Hz 120 V AC 60 Hz |
| Inrush Power In Va | 180 VA 60 Hz 170 VA 50 Hz 170 VA 50/60 Hz |
| Current Rating | 20 A tungsten 30 A fluorescent |
| Number Of Poles | 8P 8 NO |
| Control Unit | No control units |
| Pilot Light | No indicator |
| Control Circuit Fusing | 2 fuses |
| Other Options | 2P relay (1 NO + 1 NC) |
| Electrical Connection | Screw-clamp terminals |
| Height | 8.82 in (224 mm) |
| Depth | 3.27 in (83 mm) |
| Width | 5.63 in (143 mm) |

Environment

| | |
|------------------------|-------------------------|
| Enclosure Type | Not rated (open device) |
| Product Certifications | UL Listed CSA |

Ordering and shipping details

| | |
|-------------------|-----------------------|
| Category | 21322-8903 LX (NOT L) |
| Discount Schedule | CP1 |
| Returnability | No |
| Country Of Origin | MX |

Packing Units

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

| | |
|------------------------------|------------------------|
| Unit Type Of Package 1 | PCE |
| Number Of Units In Package 1 | 1 |
| Package 1 Weight | 5.90 lb(US) (2.676 kg) |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|