

# Product data sheet

Specifications



Empty enclosure control station,  
Harmony 9001K, Harmony  
9001SK, stainless steel, 3 cut  
outs, 30mm

9001KYSS3

Product availability: Stock - Normally stocked in distribution  
facility

Price\*: 372.00 USD

## Main

Range Of Product	Harmony 9001SK Harmony 9001K
Product Or Component Type	Empty enclosure
Device Short Name	9001K
Number Of Cut-Out	3 cut-outs
Cable Entry	1 entry tapped for 3/4" knockout

## Complementary

Product Destination	For Ø 30 mm control and signalling units
Material	Stainless steel
Net Weight	3.78 lb(US) (1.715 kg)

## Environment

Protective Treatment	TH
Ambient Air Temperature For Storage	-40...158 °F (-40...70 °C)
Ambient Air Temperature For Operation	-13...158 °F (-25...70 °C)
Overvoltage Category	II IEC 61140
Nema Degree Of Protection	NEMA 1 NEMA 12 NEMA 3 NEMA 4 NEMA 4X

## Ordering and shipping details

Category	US10CS121426
Discount Schedule	0CS1
Gtin	785901017509
Returnability	Yes
Country Of Origin	MX

## Packing Units

Unit Type Of Package 1	PCE
------------------------	-----

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Number Of Units In Package 1	1
Package 1 Height	5.00 in (12.7 cm)
Package 1 Width	5.20 in (13.208 cm)
Package 1 Length	11.50 in (29.21 cm)
Package 1 Weight	3.84 lb(US) (1.742 kg)

## Contractual warranty

Warranty	18 months
----------	-----------

## Sustainability





**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)


## Well-being performance

	Reach Free Of Svhc	
	Toxic Heavy Metal Free	
	Mercury Free	
	Rohs Exemption Information	Yes
Reach Regulation	<a href="#">REACH Declaration</a>	
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope) <a href="#">EU RoHS Declaration</a>	
China Rohs Regulation	<a href="#">China RoHS declaration</a>	
California Proposition 65	WARNING: This product can expose you to chemicals including: Nickel compounds, which is known to the State of California to cause cancer, and Di-isodecyl phthalate (DIDP), which is known to the State of California to cause birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>	

Dimensions Drawings

Dimensions

Below drawing shows a 3-hole enclosure. Refer to the product characteristics to get the number of holes

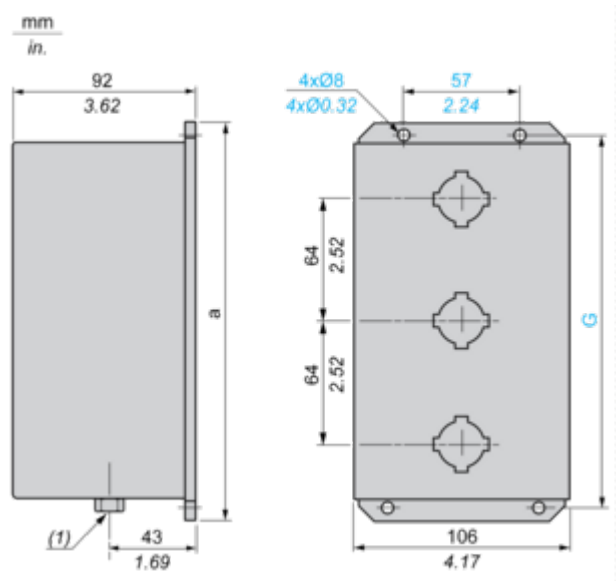

(1) Knockout conduit thread: 3/4".

a		G	
mm	in.	mm	in.
260	10.24	244	9.61