


# Product data sheet

Specifications

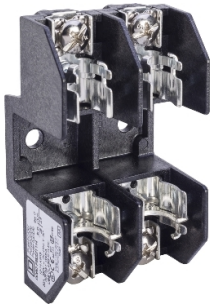

## Terminal block, Linergy, fuse holder, Class R, 30A, 250V, 2 pole

9080FB2211R

Product availability: Stock - Normally stocked in distribution facility

Price\*: 28.40 USD

### Main

Range	9080FB
Product	Fuse holder

### Complementary

Current Rating	30 A
[Ue] Rated Operational Voltage	<= 250 V AC/DC
Fuse Type	R
Fuse Size	0.5625 x 2 in
Number Of Poles	2
Electrical Connection	Pressure wire clamp
Wire Gauge	AWG 14...AWG 10 copper or aluminium
Sccr	200 kA UL 512
Product Certifications	CE UL listed file E40747 CCN IZLT CSA file 70360 class 6225 01
Operating Temperature	-40...257 °F (-40...125 °C)
Mounting Type	Surface mount
Block Material	Thermoplastic: block
Wire Stripping Length	0.4375 in (11.11 mm)
Terminal Tightening Torque	screw terminals 25 lbf.in (2.82 N.m) AWG 14...AWG 10 copper
Height	3 in (76.20 mm)
Width	1.91 in (48.51 mm)
Depth	1.38 in (35.05 mm)

### Ordering and shipping details

Category	US10CP121701
Discount Schedule	0CP1
Gtin	785901097778
Returnability	Yes
Country Of Origin	US

### Packing Units

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	1.40 in (3.556 cm)
Package 1 Width	1.90 in (4.826 cm)
Package 1 Length	3.00 in (7.62 cm)
Package 1 Weight	2.72 oz (77.111 g)

## Contractual warranty

Warranty	18 months
----------	-----------

## Sustainability

**Green Premium™** label is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

## Well-being performance

✓	Reach Free Of Svhc	
✓	Toxic Heavy Metal Free	
✓	Mercury Free	
✓	Rohs Exemption Information	Yes
Reach Regulation	REACH Declaration	
Eu Rohs Directive	Compliant	EU RoHS Declaration
China Rohs Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)	
California Proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>	