


# Product data sheet

Specifications

SQUARE D

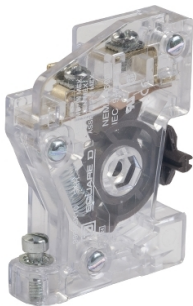

auxiliary contact Type S, 1 NC  
overlapping contact, external, field  
convertible

9999SX10

Product availability: Non-Stock - Not normally stocked in  
distribution facility

! Discontinued

## Main

|                |                          |
|----------------|--------------------------|
| Product Range  | Type S                   |
| Component Type | Auxiliary Contact Module |
| Used With      | contactor<br>starter     |

## Complementary

|                               |   |
|-------------------------------|---|
| Nema Size                     | 1<br>3<br>4<br>2<br>6<br>0<br>00<br>5<br>7  |
| Auxiliary Contact Composition | 1 NC  |
| [Uc] Control Circuit Voltage  | <= 600 V AC 50/60 Hz  |
| Rated Breaking Capacity       | 6 A 120 V AC inductive control circuit UL 508<br>3 A 240 V AC inductive control circuit UL 508<br>1.2 A 600 V AC inductive control circuit UL 508<br>1.5 A 480 V AC inductive control circuit UL 508<br>10 A <= 600 V AC resistive control circuit UL 508 |

## Environment

|                        |                                   |
|------------------------|-----------------------------------|
| Product Certifications | UL Listed<br>CSA<br>UL Recognized |
|------------------------|-----------------------------------|

## Ordering and shipping details

|                   |              |
|-------------------|--------------|
| Category          | US10CP121761 |
| Discount Schedule | 0CP1         |
| Gtin              | 785901733812 |
| Returnability     | No           |
| Country Of Origin | MX           |

## Packing Units

|                              |                   |
|------------------------------|-------------------|
| Unit Type Of Package 1       | PCE               |
| Number Of Units In Package 1 | 1                 |
| Package 1 Height             | 1.50 in (3.81 cm) |

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

|                  |                    |
|------------------|--------------------|
| Package 1 Width  | 3.00 in (7.62 cm)  |
| Package 1 Length | 4.50 in (11.43 cm) |
| Package 1 Weight | 3.36 oz (95.254 g) |

## Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

# Sustainability

**Green Premium™ label** is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)

|                       |  |
|-----------------------|--|
| Eu Rohs Directive     | Under investigation  |
| China Rohs Regulation | <a href="#">China RoHS declaration</a><br>Product out of China RoHS scope. Substance declaration for your information. |