

Product data sheet


Characteristics

AK2GD2525

Cable duct - 25 x 25 mm - without cover - grey

Product availability : Non-Stock - Not normally stocked in distribution facility

Price* : 31.20 USD

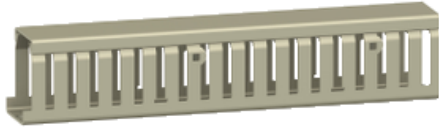

Main

Product or component type	Cable duct
Accessory / separate part category	Cabling accessories
Range compatibility	Spacial CRN Spacial S3D Thalassa PLA Thalassa PLS Thalassa PLM
Device composition	Without cover
Quantity per set	Set of 8

Complementary

Colour	Grey RAL 7030
Fixing mode	By screws Clip-on support
Material	PVC (polyvinyl chloride)
Height	0.98 in (25 mm)
Length	78.74 in (2000 mm)
Width	0.98 in (25 mm)
Product weight	0.57 lb(US) (0.26 kg)
Total number of wires	25

Environment

Ambient air temperature for operation	23...140 °F (-5...60 °C)
Flame retardance	VO conforming to UL 94
Fire resistance	1760 °F (960 °C) conforming to IEC 60695-2-1/1
Standards	DIN 43659 VDE 0506 VDE 0660

Ordering and shipping details

Category	18403 - WORLD SERVICE PARTS(ENVELOPES)
Discount Schedule	CP10

GTIN	003389110570335
Nbr. of units in pkg.	8
Package weight(Lbs)	5.9999999999999998E-2
Returnability	N
Country of origin	FR

Offer Sustainability

California proposition 65	WARNING: Cancer and Reproductive Harm - www.P65Warnings.ca.gov
---------------------------	--

Contractual warranty

Warranty period	18 months
-----------------	-----------