


Product data sheet
Characteristics

AR3307X617
NetShelter SX 48U 600mm Wide x 1200mm Deep Enclosure with Roof, No Doors or Sides, Black

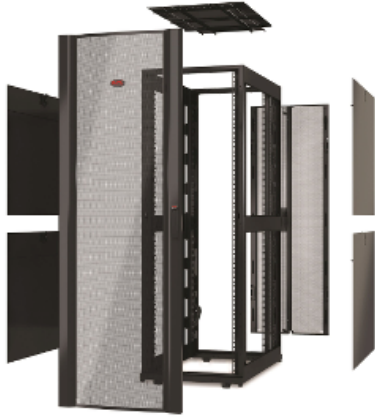

Overview

Description	Deep and Tall Universal IT Enclosure for low to medium density server and networking applications that either require additional equipment clearance space or more open space for ease of access in the rear of the enclosure. Tall to provide 48U spaces for environments that can take advantage of higher spaces and provide more mounting u-spaces at each enclosure footprint. Compact width to optimize data center space.
Model Name	NetShelter SX 48U 600mm Wide x 1200mm Deep Enclosure with Roof, No Doors or Sides, Black
Includes	Baying hardware , Key(s) , Leveling feet , Mounting Hardware , Pre-installed casters
Standard Lead Time	Usually in Stock
Product Distribution	Canada , United States

Physical

Net Weight	329.0 lbs (149.56 kg)
Maximum Height	88.9 inches (2258.0 mm)
Maximum Width	23.62 inches (600.0 mm)
Maximum Depth	47.24 inches (1200.0 mm)
Shipping Weight	364.0 lbs (165.45 kg)
Shipping Height	93.9 inches (2385.0 mm)
Shipping Width	29.38 inches (746.0 mm)
Shipping Depth	52.5 inches (1334.0 mm)
Minimum Mounting Depth	7.52
Maximum Mounting Depth	41.73
Rack Height	48 U
Color	Black
Units per Pallet	1.0
Vertical Posts	16 gauge
Roof	18 gauge
EIA Mounting Rails	14 gauge

Conformance

Approvals	UL 2416 , UL 60950-1
Standard warranty	5 year repair or replace

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Sustainable Offer Status

RoHS	Compliant
REACH	REACH: Contains No SVHCs
