


Product data sheet

Specifications

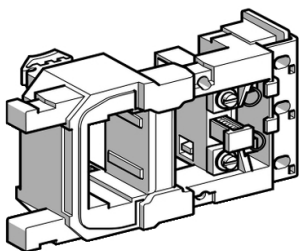

TeSys F - contactor coil - LX0FF - 48 V AC/DC

LX0FF005

⚠ Discontinued

Main

Range	TeSys
Product Or Component Type	Contactor coil
Device Short Name	LX0FF
Control Circuit Type	AC 50...400 Hz DC standard
[Uc] Control Circuit Voltage	48 V AC 50...400 Hz 48 V DC
Average Resistance	1.98 Ohm latching 68 °F (20 °C) 230.8 Ohm unlatching 68 °F (20 °C)
Product Compatibility	CR1F150
Operating Time	35...40 ms latching 50...100 ms unlatching
Mechanical Durability	1 Mcycles
Maximum Operating Rate	120 cyc/h 104 °F (40 °C)

Complementary

Control Circuit Voltage Limits	Latching: 0.85...1.1 Uc Unlatching: 0.85...1.1 Uc
--------------------------------	--

Environment

Net Weight	0.97 lb(US) (0.44 kg)
------------	-----------------------

Ordering and shipping details

Category	18401-WORLD SERVICE PARTS(CTR ACCESS)
Discount Schedule	CP10
Gtin	3389110245363
Returnability	No

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

Contractual warranty

Warranty	18 months
----------	-----------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

