


# Product data sheet

Specifications

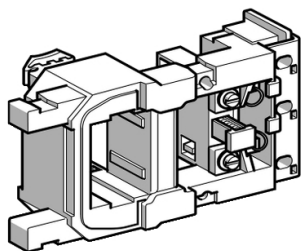

## TeSys F - contactor coil - LX0FF - 415 V AC

LX0FF011

⚠ Discontinued on: Jan 23, 2021

⚠ Discontinued

### Main

Range	TeSys
Product Or Component Type	Contactor coil
Device Short Name	LX0FF
Control Circuit Type	AC 50/60 Hz
[Uc] Control Circuit Voltage	415 V AC 50/60 Hz
Average Resistance	139.5 Ohm latching 68 °F (20 °C) 16717 Ohm unlatching 68 °F (20 °C)
Product Compatibility	CR1F150
Operating Time	35...40 ms latching 50...100 ms unlatching
Mechanical Durability	1 Mcycles
Maximum Operating Rate	120 cyc/h 104 °F (40 °C)

### Complementary

Control Circuit Voltage Limits	Latching: 0.85...1.1 Uc Unlatching: 0.85...1.1 Uc
--------------------------------	--

### Environment

Net Weight	0.97 lb(US) (0.44 kg)
------------	-----------------------

### Ordering and shipping details

Category	22341-CONTACTOR,D,K,&F ACCESS
Discount Schedule	I12
Gtin	00785901867173
Returnability	No
Country Of Origin	CZ

### Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

### Contractual warranty

Warranty	18 months
----------	-----------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

