


Product data sheet

Specifications

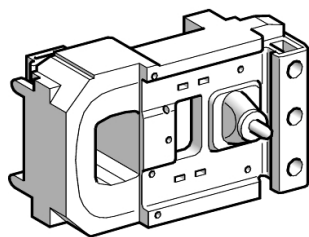

TeSys F - contactor coil - LX0FK - 380...400 V AC

LX0FK010

⚠ Discontinued on: Jul 12, 2021

⚠ Discontinued

Main

Range	TeSys
Product Or Component Type	Contactor coil
Device Short Name	LX0FK
Control Circuit Type	AC 50/60 Hz
[Uc] Control Circuit Voltage	380...400 V AC 50/60 Hz
Average Resistance	89.56 Ohm latching 68 °F (20 °C) 10570 Ohm unlatching 68 °F (20 °C)
Product Compatibility	CR1F500
Operating Time	50...100 ms unlatching 40...80 ms latching
Mechanical Durability	1 Mcycles
Maximum Operating Rate	120 cyc/h 104 °F (40 °C)

Complementary

Control Circuit Voltage Limits	Latching: 0.85...1.1 Uc Unlatching: 0.85...1.1 Uc
--------------------------------	--

Environment

Net Weight	2.69 lb(US) (1.22 kg)
------------	-----------------------

Ordering and shipping details

Category	18401-WORLD SERVICE PARTS(CTR ACCESS)
Discount Schedule	CP10
Gtin	3389110207118
Returnability	No

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	3.54 in (9 cm)
Package 1 Width	3.94 in (10 cm)
Package 1 Length	7.48 in (19 cm)
Package 1 Weight	2.59 lb(US) (1.176 kg)

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Contractual warranty

Warranty	18 months
----------	-----------