


# Product data sheet

Specifications

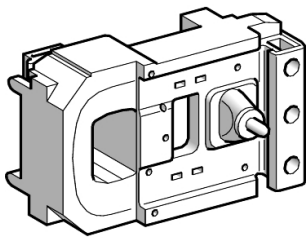

## TeSys F - contactor coil - LX0FK - 415 V AC

LX0FK011

! Discontinued

### Main

Range	TeSys
Product Or Component Type	Contactor coil
Device Short Name	LX0FK
Control Circuit Type	AC 50/60 Hz
[Uc] Control Circuit Voltage	415 V AC 50/60 Hz
Average Resistance	112.06 Ohm latching 68 °F (20 °C) 13256 Ohm unlatching 68 °F (20 °C)
Product Compatibility	CR1F500
Operating Time	50...100 ms unlatching 40...80 ms latching
Mechanical Durability	1 Mcycles
Maximum Operating Rate	120 cyc/h 104 °F (40 °C)

### Complementary

Control Circuit Voltage Limits	Latching: 0.85...1.1 Uc Unlatching: 0.85...1.1 Uc
--------------------------------	--

### Environment

Net Weight	2.69 lb(US) (1.22 kg)
------------	-----------------------

### Ordering and shipping details

Category	18401-WORLD SERVICE PARTS(CTR ACCESS)
Discount Schedule	CP10
Gtin	3389110207132
Returnability	No

### Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

### Contractual warranty

Warranty	18 months
----------	-----------

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications