


Price** : 394.00 USD

LX4FH055 has not been replaced. Please contact your customer care center for more information.

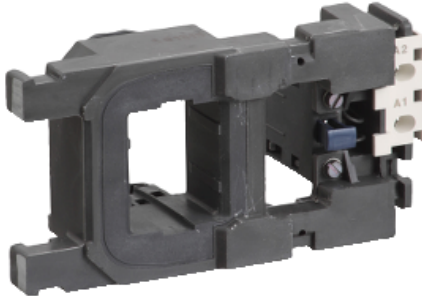

ⓘ Discontinued

Main

Range	TeSys
Product or component type	Contacteur coil
Device short name	LX4FH
Range compatibility	TeSys F LC1F contacteur
Product compatibility	LC1F265 LC1F330
Control circuit type	DC wide range
[Uc] control circuit voltage	55 V DC
Average resistance	4.37 Ohm inrush 68 °F (20 °C) 994.1 Ohm holding 68 °F (20 °C)
Operating time	40...50 ms closing 40...65 ms opening

Complementary

Coil technology	Without built-in suppressor module
Control circuit voltage limits	Operational 0.85...1.1 Uc 131 °F (55 °C) Drop-out 0.15...0.2 Uc 131 °F (55 °C)

Environment

Ambient air temperature for operation	23...131 °F (-5...55 °C)
---------------------------------------	--------------------------

Ordering and shipping details

Category	18401-WORLD SERVICE PARTS(CTR ACCESS)
Discount Schedule	CP10
GTIN	03389118114333
Package weight(Lbs)	1.63 lb(US) (0.740 kg)
Returnability	No

Contractual warranty

Warranty	18 months
----------	-----------