


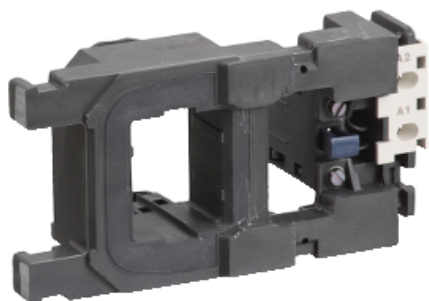

Price\*\* : 394.00 USD

LX4FH170 has not been replaced. Please contact your customer care center for more information.



ⓘ Discontinued

### Main

Range	TeSys
Product or component type	Contactor coil
Device short name	LX4FH
Range compatibility	TeSys F LC1F contactor
Product compatibility	LC1F265 LC1F330
Control circuit type	DC low consumption
[Uc] control circuit voltage	170 V DC
Average resistance	65.7 Ohm inrush 68 °F (20 °C) 11500 Ohm holding 68 °F (20 °C)
Inductance of closed circuit	1590 H
Operating time	40...50 ms closing 40...65 ms opening
Mechanical durability	10 Mcycles
Maximum operating rate	2400 cyc/h 131 °F (55 °C)

### Complementary

Coil technology	Without built-in suppressor module
Control circuit voltage limits	Operational 0.85...1.1 Uc 131 °F (55 °C) Drop-out 0.15...0.2 Uc 131 °F (55 °C)
Inrush power in W	750 W 68 °F (20 °C)
Hold-in power consumption in W	5 W 68 °F (20 °C)

### Environment

Ambient air temperature for operation	23...131 °F (-5...55 °C)
Net weight	1.63 lb(US) (0.74 kg)

### Ordering and shipping details

Category	18401-WORLD SERVICE PARTS(CTR ACCESS)
----------	---------------------------------------

Discount Schedule	CP10
GTIN	03389118114241
Package weight(Lbs)	1.63 lb(US) (0.740 kg)
Returnability	No
Country of origin	FR

### Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: which is known to the State of California to cause Not determined harm. For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>
RECh Regulation	<a href="#">RECh Declaration</a>
RECh free of SVHC	Yes
EU RoHS Directive	Not applicable, out of EU RoHS legal scope
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a>
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	<a href="#">End of Life Information</a>

### Contractual warranty

Warranty	18 months
----------	-----------