


Price** : 138.00 USD

LX4FH190 has not been replaced. Please contact your customer care center for more information.

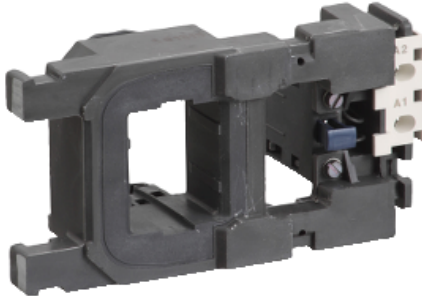

⚠ Discontinued

Main

| | |
|------------------------------|---|
| Range | TeSys |
| Product or component type | Contactor coil |
| Device short name | LX4FH |
| Range compatibility | TeSys F LC1F contactor |
| Product compatibility | LC1F330 LC1F265 |
| Control circuit type | DC wide range |
| [Uc] control circuit voltage | 190 V DC |
| Average resistance | 52.32 Ohm inrush 68 °F (20 °C) 11242 Ohm holding 68 °F (20 °C) |
| Operating time | 40...50 ms closing 40...65 ms opening |

Complementary

| | |
|--------------------------------|---|
| Coil technology | Without built-in suppressor module |
| Control circuit voltage limits | Operational 0.85...1.1 Uc 131 °F (55 °C)) Drop-out 0.15...0.2 Uc 131 °F (55 °C)) |

Environment

| | |
|---------------------------------------|--------------------------|
| Ambient air temperature for operation | 23...131 °F (-5...55 °C) |
|---------------------------------------|--------------------------|

Ordering and shipping details

| | |
|---------------------|-------------------------------|
| Category | 22341-CONTACTOR,D,K,&F ACCESS |
| Discount Schedule | I12 |
| GTIN | 00785901161448 |
| Package weight(Lbs) | 1.85 lb(US) (0.841 kg) |
| Returnability | No |
| Country of origin | CZ |

Contractual warranty

| | |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|