


Product data sheet

Specifications

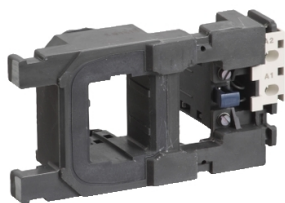

contactor coil - FH - 300 V DC

LX4FH300

⚠ Discontinued on: Jan 23, 2021

⚠ Discontinued

Main

Range	TeSys
Product Or Component Type	Contactor coil
Device Short Name	LX4FH
Range Compatibility	TeSys TeSys F LC1F contactor
Product Compatibility	LC1F265 LC1F330
Control Circuit Type	DC wide range
[Uc] Control Circuit Voltage	300 V DC
Average Resistance	131.7 Ohm inrush 68 °F (20 °C) 22260 Ohm holding 68 °F (20 °C)
Operating Time	40...50 ms closing 40...65 ms opening

Complementary

Coil Technology	Without built-in suppressor module
Control Circuit Voltage Limits	Operational 0.85...1.1 Uc 131 °F (55 °C)) Drop-out 0.15...0.2 Uc 131 °F (55 °C))

Environment

Ambient Air Temperature For Operation	23...131 °F (-5...55 °C)
---------------------------------------	--------------------------

Ordering and shipping details

Category	18401-WORLD SERVICE PARTS(CTR ACCESS)
Discount Schedule	CP10
Gtin	3389118114227
Returnability	No
Country Of Origin	CZ

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1

Contractual warranty

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Warranty

18 months