


Price\*\* : 394.00 USD

LX4FH300 has not been replaced. Please contact your customer care center for more information.

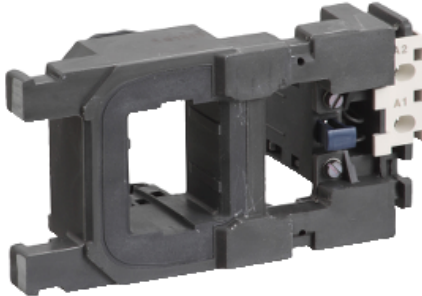

ⓘ Discontinued

### Main

Range	TeSys
Product or component type	Contactor coil
Device short name	LX4FH
Range compatibility	TeSys F LC1F contactor
Product compatibility	LC1F265 LC1F330
Control circuit type	DC wide range
[Uc] control circuit voltage	300 V DC
Average resistance	131.7 Ohm inrush at 68 °F (20 °C) 22260 Ohm holding at 68 °F (20 °C)
Operating time	40...50 ms closing 40...65 ms opening

### Complementary

Coil technology	Without built-in suppressor module
Control circuit voltage limits	0.15...0.2 Uc at 131 °F (55 °C) drop-out 0.85...1.1 Uc at 131 °F (55 °C) operational

### Environment

Ambient air temperature for operation	> 23...131 °F (> -5...55 °C)
---------------------------------------	------------------------------

### Ordering and shipping details

Category	18401 - WORLD SERVICE PARTS(CTR ACCESS)
Discount Schedule	CP10
Nbr. of units in pkg.	1
Package weight(Lbs)	1.6300000000000001
Returnability	N
Country of origin	CZ

### Contractual warranty

Warranty period	18 months
-----------------	-----------