

# Product data sheet


## Characteristics

# NSYCCOTHCF

ClimaSys CC - simple thermostat 250V - range of temperature 0...60°C - NC - °F

Product availability : Stock - Normally stocked in distribution facility

Price\* : 47.40 USD

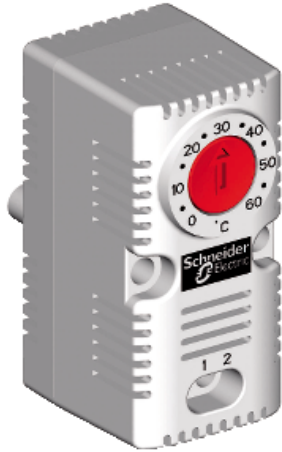

### Main

Range	ClimaSys
Product name	ClimaSys CC
Product or component type	Simple thermostat
Temperature setting range	32...140 °F (0...60 °C)
Information displayed	Temperature in °F

### Complementary

Input voltage	250 V
Sensor type	Bimetal
Contacts type and composition	NC
Contact resistance	< 10 mOhm
Service life in cycles	>= 100000 cycles
Maximum switching capacity	10 A 250 V AC resistive 15 A 120 V AC resistive 30 W DC 2 A 120...250 V AC inductive pf: 0.6
Electrical connection	4 terminals 2.5 mm <sup>2</sup>
Mounting mode	Clipped
Height	External: 2.68 in (68 mm)
Width	External: 1.3 in (33 mm)
Depth	External: 1.73 in (44 mm)
Product weight	1.41 oz (40 g)
Mounting location	On mounting plate Spacial upright Cross rails 35 mm DIN rail
Ambient air temperature for operation	-4...176 °F (-20...80 °C)
IP degree of protection	IP20
Hysteresis	7 %
Number of outputs	1 output(s) heating function
Material	PC
Color	Light grey

Flame retardance	Self-extinguishing conforming to UL94 (material V0)
Product certifications	UL

**Ordering and shipping details**

Category	80036 - ENCLOSURE SYSTEMS ACCESSORIES
Discount Schedule	ES1
GTIN	00785901910138
Nbr. of units in pkg.	1
Package weight(Lbs)	0.14999999999999999
Returnability	Y
Country of origin	DE

**Offer Sustainability**

RoHS (date code: YYWW)	Compliant - since 0940 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
California proposition 65	WARNING: This product can expose you to chemicals including:
----- Substance 1	Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm.
----- More information	For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>

**Contractual warranty**

Warranty period	18 months
-----------------	-----------