


Product availability : Non-Stock - Not normally stocked in distribution facility

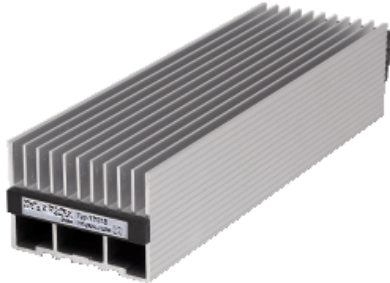

### Main

Range	ClimaSys
Product name	ClimaSys CR
Product or component type	Resistance heater
Range compatibility	Prisma P Prisma G
Power range	55 W
Input voltage	110...250 V AC 50/60 Hz

### Complementary

Operating position	Vertical
Ambient air temperature for operation	-40...158 °F (-40...70 °C)
IP degree of protection	IP20
Product certifications	UL VDE
Material	Extruded aluminium body
Height	7.87 in (200 mm)
Width	85 mm
Depth	2.76 in (70 mm)
Condition of use	Electrical protection is needed Heaters must be installed with a thermal controller Air sealed enclosure
Fixing mode	By clips
Mounting support	35 mm DIN rail

### Ordering and shipping details

Category	80036 - ENCLOSURE SYSTEMS ACCESSORIES
Discount Schedule	ES1
GTIN	003606480152160
Nbr. of units in pkg.	1
Package weight(Lbs)	1.01
Returnability	N
Country of origin	ES

Offer Sustainability

RoHS (date code: YYWW)	Compliant <a href="#">Schneider Electric declaration of conformity</a>
REACH	Reference not containing SVHC above the threshold <a href="#">Reference not containing SVHC above the threshold</a>
California proposition 65	WARNING: Cancer and Reproductive Harm - <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>

Contractual warranty

Warranty period	18 months
-----------------	-----------