

Product data sheet

Characteristics


NSYFXT6040

Fixed tray H30xW482xD290 mm for enclosure of
W600xD400 mm - maximum load 150 kg

Product availability : Non-Stock - Not normally stocked in distribution facility



Price* : 189.83 USD

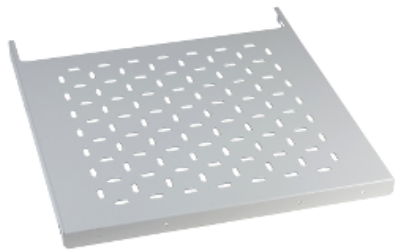

Main

Range	Spacial
Accessory / separate part category	Installation accessory
Product or component type	Fixed tray
Application	Multi-purpose
For enclosure nominal dimensions	D: 600 mm 400 mm
Mounting support	Direct to the structure 40 mm cross rails
Range compatibility	Spacial SF Spacial SM
Device composition	Fixing elements 1 fixed tray
Quantity per set	Set of 1

Complementary

Material	Steel
Colour	Grey RAL 7035
Surface finish	Epoxy-polyester powder
Adjustment	Adjustable in depth every 25 mm
Maximum load	150 kg evenly distributed
Height	1.18 in (30 mm)
Width	18.98 in (482 mm)
Depth	11.42 in (290 mm)

Ordering and shipping details

Category	80035 - ENCLOSURE SYSTEMS FLOOR MOUNT
Discount Schedule	ES1

GTIN	003606480064494
Nbr. of units in pkg.	1
Package weight(Lbs)	6.7800000000000002
Returnability	N
Country of origin	FR

Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold
Product environmental profile	Available
Product end of life instructions	Need no specific recycling operations
California proposition 65	WARNING: Cancer and Reproductive Harm - www.P65Warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------