

Product data sheet


Characteristics

NSYLN35290

Adjustable cable tie 295x3.6 black . Polyamide 6/6. Composition: 1000 units.

Price* : 143.95 USD

NSYLN35290 has not been replaced. Please contact your customer care center for more information.

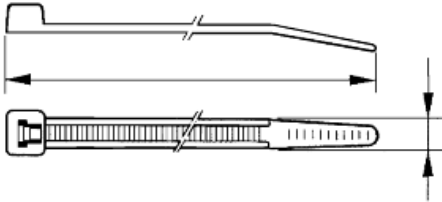

! Discontinued

Main

Accessory / separate part category	Cable management accessory
Product or component type	Cable tie
Application	Multi-purpose
Device composition	Cable tie 1
Quantity per set	Set of 1000

Complementary

Mounting support	Cable ties fixing supports
Material	Polyamide 6/6 black
Length	11.61 in (295 mm)
Width	0.14 in (3.6 mm)

Environment

Fire resistance	1202 °F (650 °C) conforming to UL 94 V2
Environmental characteristic	Not sensitive to engine oil, greases, oil products, etc Good resistance to bases and organic acids, chlorinated solvent Not resistant to phenol
Maximum tightening diameter	2.99 in (76 mm)
Minimum pulling resistance	13.6 Ohm

Ordering and shipping details

Category	80036 - ENCLOSURE SYSTEMS ACCESSORIES
Discount Schedule	ES1
Nbr. of units in pkg.	100
Package weight(Lbs)	0
Returnability	N
Country of origin	TW

Offer Sustainability

RoHS (date code: YYWW)	Compliant
	Schneider Electric declaration of conformity

REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold
-------	--

Contractual warranty

Warranty period	18 months
-----------------	-----------
