


NSYMR53

Monobloc perforated plates H500xW300mm with universal perforations 11x26mm

Product availability : Non-Stock - Not normally stocked in distribution facility



Price** : 22.55 USD

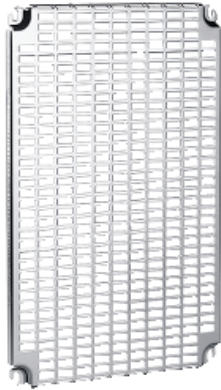

Main

Range	Spacial
Accessory / separate part category	Mounting accessory
Product or component type	Mounting plate
Application	Multi-purpose
For enclosure nominal dimensions	19.69 in (500 mm) 11.81 in (300 mm)
Mounting location	Step slide Direct fixing on backstuds
Mounting plate description	Telequick perforated
Range compatibility	Spacial S3D Spacial CRN Spacial S3X Thalassa PLM
Quantity per set	Set of 1
Material	steel
Surface finish	Zinc coated

Complementary

Fixing mode	Screwed on backstuds M8 By fixing element
Height	178.62 in (4537 mm)
Width	9.88 in (251 mm)
Depth	0.59 in (15 mm)
Thickness	0.08 in (2 mm)
Net weight	1.85 lb(US) (0.838 kg)
Number of slots	261
Variant particularity	Installation in rear of enclosure
Cut-out dimensions	11 x 26 mm

Ordering and shipping details

Category	80036 - ENCLOSURE SYSTEMS ACCESSORIES
Discount Schedule	ES1
GTIN	03606480183676
Package weight(Lbs)	8.61 kg (18.98 lb(US))
Returnability	No
Country of origin	FR

Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: No which is known to the State of California to cause No harm. For more information go to www.p65warnings.ca.gov
REACH Regulation	REACH Declaration
REACH free of SVHC	Yes
EU RoHS Directive	Not applicable, out of EU RoHS legal scope
Toxic heavy metal free	Yes
Mercury free	Yes
RoHS exemption information	Yes
China RoHS Regulation	China RoHS declaration Pro-active China RoHS declaration (out of China RoHS legal scope)
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations

Contractual warranty

Warranty	18 months
----------	-----------