


Product data sheet

Specifications

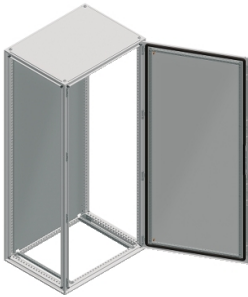

Spacial SF enclosure without mounting plate - assembled - 2000x1000x600 mm

NSYSF201060

Product availability: Non-Stock - Not normally stocked in distribution facility

Price*: 1,626.38 USD

Main

Range	Spacial
Extended Range	Spacial SF
Application	Multi-purpose
Product Or Component Type	Suitable enclosure
Enclosure Nominal Height	78.74 in (2000 mm)
Enclosure Nominal Width	39.37 in (1000 mm)
Enclosure Nominal Depth	23.62 in (600 mm)
Enclosure Mounting	Floor-standing
Device Composition	2 sliding rails 4 mounting plate bracket 1 structure 1 door 1 locking system with handle door 1 rear panel 1 roof

Complementary

Structure Type	Vertical uprights joined with top and bottom frames Panels and doors built into the structure Formed from a single section Perforated structure with a pitch of 25 mm
Door Opening Side	Reversible 120 °)
Door Type	Solid front
Mounting Plate Description	Without mounting plate
Type Of Gland Plate	Without gland plate
Lock Type	4 points lock, handle with 5 mm double bar insert front door
Number Of Doors	Front 1
Accessibility For Operation	Rear Front Sides of enclosure
Removable Parts	Door by screws hinge Rear panel by screws Roof by screws Mounting plate bracket by screws Sliding rail by screws

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Material	Frame galvanised steel Uprights galvanised steel Door sheet steel Panels sheet steel Hinge zamak Handle polyamide 6 with 30 % fibre glass
Surface Finish	epoxy-polyester powder
Color	Enclosure Gray RAL 7035) Handle Black RAL 9005)
Net Weight	280.43 lb(US) (127.2 kg)

Environment

Standards	IEC 62208
Nema Degree Of Protection	NEMA 3R/12
Ip Degree Of Protection	IP55 IEC 60529
Ik Degree Of Protection	IK10 IEC 62262

Ordering and shipping details

Category	US10ES180035
Discount Schedule	0ES1
Gtin	3606485118406
Returnability	No
Country Of Origin	ES

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	83.86 in (213.0 cm)
Package 1 Width	41.14 in (104.5 cm)
Package 1 Length	27.17 in (69.0 cm)
Package 1 Weight	280.43 lb(US) (127.2 kg)

Contractual warranty

Warranty	18 months
----------	-----------

Sustainability



Green Premium™ label is Schneider Electric’s commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO₂ products.

Guide to assessing product sustainability is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product’s sustainability >](#)



Transparency RoHS/REACH

Well-being performance

 Mercury Free

 RoHS Exemption Information [Yes](#)

Certifications & Standards

Reach Regulation	REACH Declaration
Eu Rohs Directive	Pro-active compliance (Product out of EU RoHS legal scope)
China Rohs Regulation	China RoHS declaration Product out of China RoHS scope. Substance declaration for your information.
Environmental Disclosure	Product Environmental Profile
Circularity Profile	No need of specific recycling operations