




Price\*\* : 2,638.87 USD

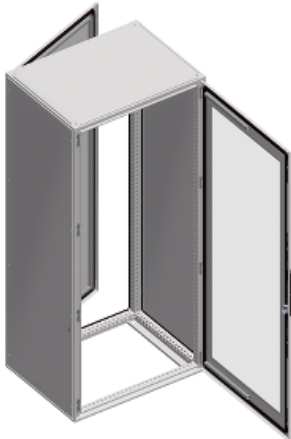

### Main

Range	Spacial
Extended range	Spacial SF-E
Application	Electronic application
Product or component type	Suitable enclosure
Enclosure nominal height	78.74 in (2000 mm)
Enclosure nominal width	31.50 in (800 mm)
Enclosure nominal depth	31.50 in (800 mm)
Enclosure mounting	Floor-standing
Device composition	1 structure 1 locking system with handle door 1 roof 2 door front and rear 2 side panels

### Complementary

Structure type	Vertical uprights joined with top and bottom frames Formed from a single section Perforated structure with a pitch of 25 mm Panels and doors built into the structure
Door type	Plain front Glazed rear
Number of doors	Front and rear 2
Door opening side	Reversible 120 °)
Lock type	4 points lock, handle with 5 mm double bar insert front and rear doors
Mounting plate description	Without mounting plate
Type of gland plate	Without gland plate
Accessibility for operation	Rear Front Sides of enclosure

Removable parts	Door by screws hinge Roof by screws Side panel by screws
Material	Frame galvanised steel Uprights galvanised steel Door sheet steel Panels sheet steel Hinge zamak Handle polyamide 6 with 30 % fibre glass
Surface finish	epoxy-polyester powder
Color	Enclosure grey RAL 7035) Handle black RAL 9005)

## Environment

Standards	IEC 62208
IP degree of protection	IP55 IEC 60529
IK degree of protection	IK08 IEC 62262 of transparent door) IK10 IEC 62262 of plain door)

## Ordering and shipping details

Category	80035 - ENCLOSURE SYSTEMS FLOOR MOUNT
Discount Schedule	ES1
GTIN	03606485127392
Package weight(Lbs)	134.72 kg (297 lb(US))
Returnability	No
Country of origin	FR

## Offer Sustainability

Sustainable offer status	Green Premium product
California proposition 65	WARNING: This product can expose you to chemicals including: No which is known to the State of California to cause No harm. For more information go to <a href="http://www.p65warnings.ca.gov">www.p65warnings.ca.gov</a>
REACH Regulation	<a href="#">REACH Declaration</a>
EU RoHS Directive	Not applicable, out of EU RoHS legal scope
Mercury free	Yes
RoHS exemption information	<a href="#">Yes</a>
China RoHS Regulation	<a href="#">China RoHS declaration</a> Product out of China RoHS scope. Substance declaration for your information.
Environmental Disclosure	<a href="#">Product Environmental Profile</a>
Circularity Profile	No need of specific recycling operations

## Contractual warranty

Warranty	18 months
----------	-----------