


PCSPCTFCL200018

AccuSine+ current transformer - 2000/1 - Round
Split Core - diam: 203.2mm

Product availability : Non-Stock - Not normally stocked in distribution facility



Price* : 2,339.00 USD

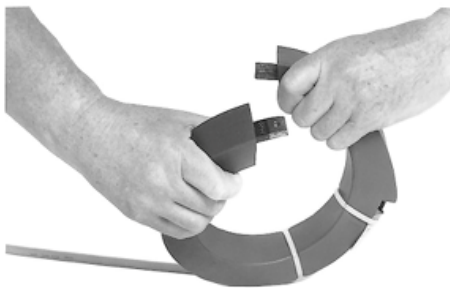

Main

Range	AccuSine
Product or component type	Current transformer
Accessory / separate part category	Measurement accessory
Range compatibility	AccuSine PCS+ active harmonic filter AccuSine PFV+ electronic VAR controller
Current transformer type	Split core balance
Secondary current	1 A

Complementary

Current transformer ratio	2000/1
Electrical connection	Flying lead 3.65 m 720 V
Input impedance	18 Ohm
Line Rated Current	2000 A
Thermal factor	1.25 at θ 86 °F (30 °C) 1 at θ 131 °F (55 °C)
Network frequency	50...400 Hz
Measurement accuracy	1 %
Accuracy class	Class 1
System Voltage	< 720 V AC at 50...400 Hz
[Uimp] rated impulse withstand voltage	10 kV (50 μ s)
Depth	1.5 in (38.1 mm) outside
Diameter	Inner: 203.2 mm Outer: 266.7 mm
Product weight	5.51 lb(US) (2.5 kg)

Environment

Standards	IEC 60044-1
Product certifications	cURus CE
Ambient air temperature for operation	-49...131 °F (-45...55 °C)

Ordering and shipping details

Category	00089 - ACTIVE FILTERS
Discount Schedule	DE2C
GTIN	003606480891861
Nbr. of units in pkg.	1
Package weight(Lbs)	5.5
Returnability	N
Country of origin	US