

Product data sheet

Characteristics

PCSPCTFCL300016


AccuSine+ current transformer - 3000/1 - Round Split Core - diam: 152.4mm

Product availability : Non-Stock - Not normally stocked in distribution facility



Price* : 2,096.00 USD

PCSPCTFCL300016 has not been replaced. Please contact your customer care center for more information.

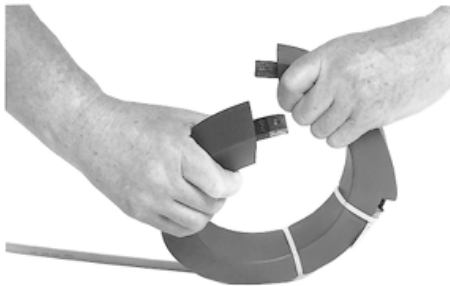

! Discontinued

Main

Range	AccuSine
Product or component type	Current transformer
Accessory / separate part category	Measurement accessory
Range compatibility	AccuSine PCS+ active harmonic filter AccuSine PFV+ electronic VAR controller
Current transformer type	Split core balance
Secondary current	1 A

Complementary

Current transformer ratio	3000/1
Electrical connection	Flying lead 3.65 m 720 V
Input impedance	520 Ohm
Line Rated Current	3000 A
Thermal factor	1.25 at θ 86 °F (30 °C) 1 at θ 131 °F (55 °C)
Network frequency	50...400 Hz
Measurement accuracy	1 %
Accuracy class	Class 1
System Voltage	< 720 V AC at 50...400 Hz
[Uimp] rated impulse withstand voltage	10 kV (50 μ s)
Depth	1.5 in (38.1 mm) outside
Diameter	Inner : 152.4 mm Outer : 215.9 mm
Product weight	4.19 lb(US) (1.9 kg)

Environment

Standards	IEC 60044-1
-----------	-------------

Product certifications	cURus CE
Ambient air temperature for operation	-49...131 °F (-45...55 °C)

Ordering and shipping details

Category	00089 - ACTIVE FILTERS
Discount Schedule	DE2C
GTIN	003606480891977
Nbr. of units in pkg.	1
Package weight(Lbs)	4.410000000000001
Returnability	N