


# Product data sheet

Specifications

SQUARE D

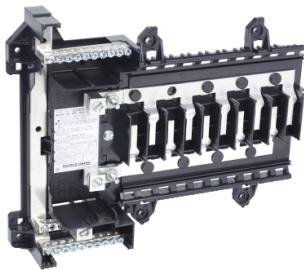

Load center interior, QO, 1 phase, 32 spaces, 32 circuits, 125A convertible main lugs, NEMA1, gnd bar, UL

QO132L125GI

Discontinued

Discontinued on: Mar 11, 2022

Product availability: Non-Stock - Not normally stocked in distribution facility

## Main

|  |                          |
|--|--------------------------|
| Product Type                           | Load Center Interior     |
| Marketing Trade Name                   | QO                       |
| Load Center Type                       | Convertible Mains (lugs) |
| Rated Current                          | 125 A                    |
| Number Of Spaces                       | 32                       |
| Max Short Circuit Current Rating       | 65 kA                    |
| Maximum Number Of Single Pole Circuits | 32                       |
| Maximum Number Of Tandem Breakers      | 0                        |
| Number Of Phases                       | 1 phase                  |
| Voltage Rating                         | 120/240 V AC             |

## Complementary

|                        |  |
|------------------------|--|
| Ground Bar             | Grounding bar included (not installed) |
| Busbar Material        | Tin plated copper: busbar              |
| Product Certifications | UL Listed                              |
| Tightening Torque      | 5.6 N.m, AWG 6...AWG 2/0               |

## Environment

|                                       |                                 |
|---------------------------------------|---------------------------------|
| Ambient Air Temperature For Operation | 23 °F (-5 °C)<br>104 °F (40 °C) |
|---------------------------------------|---------------------------------|

## Ordering and shipping details

|                   |              |
|-------------------|--------------|
| Category          | US10DE500199 |
| Discount Schedule | 0DE5         |
| Returnability     | No           |

## Packing Units

|                              |                        |
|------------------------------|------------------------|
| Unit Type Of Package 1       | PCE                    |
| Number Of Units In Package 1 | 1                      |
| Package 1 Weight             | 14.00 lb(US) (6.35 kg) |

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

# Contractual warranty

|          |           |
|----------|-----------|
| Warranty | 18 months |
|----------|-----------|

## Sustainability

**Green Premium™ label** is Schneider Electric's commitment to delivering products with best-in-class environmental performance. Green Premium promises compliance with the latest regulations, transparency on environmental impacts, as well as circular and low-CO<sub>2</sub> products.

**Guide to assessing product sustainability** is a white paper that clarifies global eco-label standards and how to interpret environmental declarations.

[Learn more about Green Premium >](#)

[Guide to assess a product's sustainability >](#)

## Well-being performance

|   |   |   |
|---|---|---|
|  | Reach Free Of Svhc  |   |
|  | Toxic Heavy Metal Free  |   |
|  | Mercury Free  |   |
|  | Rohs Exemption Information  | Yes   |
| Eu Rohs Directive   | Compliant   | <a href="#">EU RoHS Declaration</a>                               |
| China Rohs Regulation   | <a href="#">China RoHS declaration</a>  | Pro-active China RoHS declaration (out of China RoHS legal scope) |
| California Proposition 65   | WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to <a href="#">www.P65Warnings.ca.gov</a> |   |