

# Product data sheet


## Characteristics

# S29383

## 60VDC H/J/L-FRAME SHUNT TRIP

Product availability : Non-Stock - Not normally stocked in distribution facility

Price\*\* : 717.00 USD

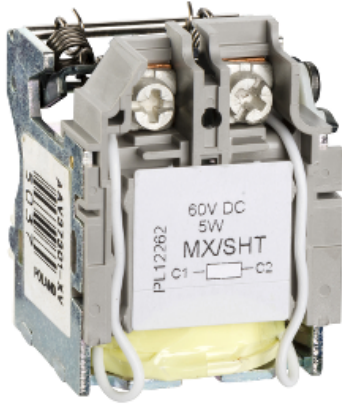

### Main

Product or component type	Shunt trip
Circuit breaker type	J-frame L-Frame H-frame

### Complementary

Rated voltage	60 V DC
Tightening torque	1.4 N.m for 0.82...2.5 mm <sup>2</sup> (AWG 18...AWG 14)

### Environment

Product certifications	CSA
------------------------	-----

### Ordering and shipping details

Category	01103 - H,J,COMPACT NS UL/IEC CIRCUIT BREAKER ACCESSORIES
Discount Schedule	DE2
Nbr. of units in pkg.	1
Package weight(Lbs)	1
Returnability	Y
Country of origin	US

### Offer Sustainability

RoHS (date code: YYWW)	Will be compliant on 4Q2016 <a href="#">Will be compliant on 4Q2016</a>
California proposition 65	WARNING: Cancer and Reproductive Harm - <a href="http://www.P65Warnings.ca.gov">www.P65Warnings.ca.gov</a>

### Contractual warranty

Warranty period	18 months
-----------------	-----------