


Product availability : Non-Stock - Not normally stocked in distribution facility

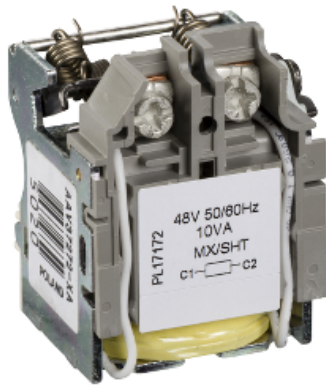

Price** : 717.00 USD



Main

Product or component type	Shunt trip
Circuit breaker type	H-frame J-frame L-Frame

Complementary

Rated voltage	48 V AC
Tightening torque	1.4 N.m for 0.82...2.5 mm ² (AWG 18...AWG 14)

Environment

Product certifications	CSA
------------------------	-----

Ordering and shipping details

Category	01103 - H,J,COMPACT NS UL/IEC CIRCUIT BREAKER ACCESSORIES
Discount Schedule	DE2
Nbr. of units in pkg.	1
Package weight(Lbs)	1
Returnability	Y
Country of origin	US

Offer Sustainability

Sustainable offer status	Green Premium product
RoHS (date code: YYWW)	Compliant - since 0938 - Schneider Electric declaration of conformity Schneider Electric declaration of conformity
REACH	Reference not containing SVHC above the threshold Reference not containing SVHC above the threshold
Product environmental profile	Available

Product end of life instructions	Need no specific recycling operations
California proposition 65	WARNING: Cancer and Reproductive Harm - www.P65Warnings.ca.gov

Contractual warranty

Warranty period	18 months
-----------------	-----------
