


# Product data sheet

Specifications

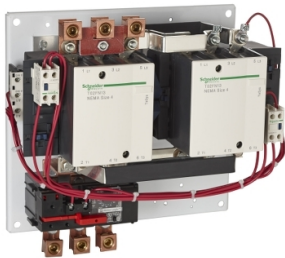

## TeSys NEMA Sz 3 rev open starter, 3P, 208 VAC

T36EN23L6

! Discontinued

### Main

Product	Starter
Range Of Product	TeSys N
Current Rating	90 A
Certifications	UL Listed CSA
Control Circuit Type	Common control circuit
Enclosure Type	Not rated (open device)
Auxiliary Contacts	1 NO
Horsepower Rating	25 HP 200 V AC 30 HP 230 V AC 50 HP 460 V AC 50 HP 575 V AC
Number Of Poles	3P
Phase	3 phase
Maximum Voltage Rating	600 V AC
Nema Size	3
Control Circuit Voltage	208 V AC
Starter Type	Reversing
Electrical Connection	Lugs ordered separately
Overload Type	Solid state Motor Logic class 10/20 30...90 A

### Ordering and shipping details

Category	21199-TESYS N STARTERS SIZES 3 - 7
Discount Schedule	CP1
Returnability	No
Country Of Origin	CZ

### Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Weight	26.20 lb(US) (11.884 kg)

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications