




Product data sheet

Specifications

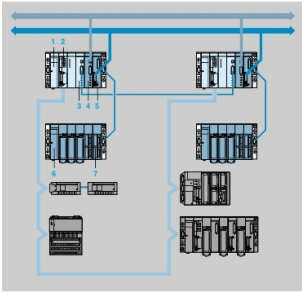

Ethernet TCP/IP module - 10 Mbit/s - web server class A10

TSXETY210

-  **Discontinued on:** Dec 2, 2020
-  **To be end-of-service on:** Dec 31, 2026

 **Discontinued - Service only**

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

Range Of Product	Modicon Premium Automation platform
Product Or Component Type	Ethernet TCP/IP module
Automation Architecture	Premium Warm Standby
Physical Interface	AUI - 100BASE-5 1 AUI cable RJ45 - 10BASE-T 1 twisted pair
Transmission Rate	10 Mbit/s
Communication Service	Modbus TCP messaging SNMP agent Uni-TE messaging Common words, Ethway/X-Way
Supply	Via the power supply of the rack
Local Signalling	for collision detection (COL) 1 LED for Ethernet network status (RUN) 1 LED for Ethernet port fault (ERR) 1 LED for transmission/reception activity (TX/TR) 1 LED

Complementary

Communication Port Protocol	Modbus TCP Ethway/X-Way Uni-Telway
Maximum Number Of Connections	64
Web Server	Transparent ready class A10
Marking	CE
Product Compatibility	PL7 Pro Unity Pro
Current Consumption	1200 mA 5 V DC with remote power supply (AUI) 800 mA 5 V DC without remote power supply (RJ45)
Module Format	Standard
Net Weight	0.75 lb(US) (0.34 kg)

Environment

Standards	FM Class 1 Division 2 group C FM Class 1 Division 2 group A FM Class 1 Division 2 group B FM Class 1 Division 2 group D EN 61131-2
-----------	--

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Product Certifications	UL 508 CSA 1010-1
Ip Degree Of Protection	IP20
Ambient Air Temperature For Operation	32...140 °F (0...60 °C)
Relative Humidity	10...95 % 140 °F (60 °C) without condensation

Ordering and shipping details

Category	US1PC2222558
Discount Schedule	PC22
Gtin	3389110195941
Returnability	No
Country Of Origin	FR

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.17 in (5.5 cm)
Package 1 Width	7.09 in (18.0 cm)
Package 1 Length	10.24 in (26.0 cm)
Package 1 Weight	17.07 oz (484.0 g)
Unit Type Of Package 2	S04
Number Of Units In Package 2	12
Package 2 Height	11.81 in (30.0 cm)
Package 2 Width	15.75 in (40.0 cm)
Package 2 Length	23.62 in (60.0 cm)
Package 2 Weight	14.89 lb(US) (6.755 kg)


Contractual warranty

Warranty	18 months
----------	-----------

Dimensions Drawings

Standard and Extendable Racks for Modules Mounting

Dimensions of Modules and Racks

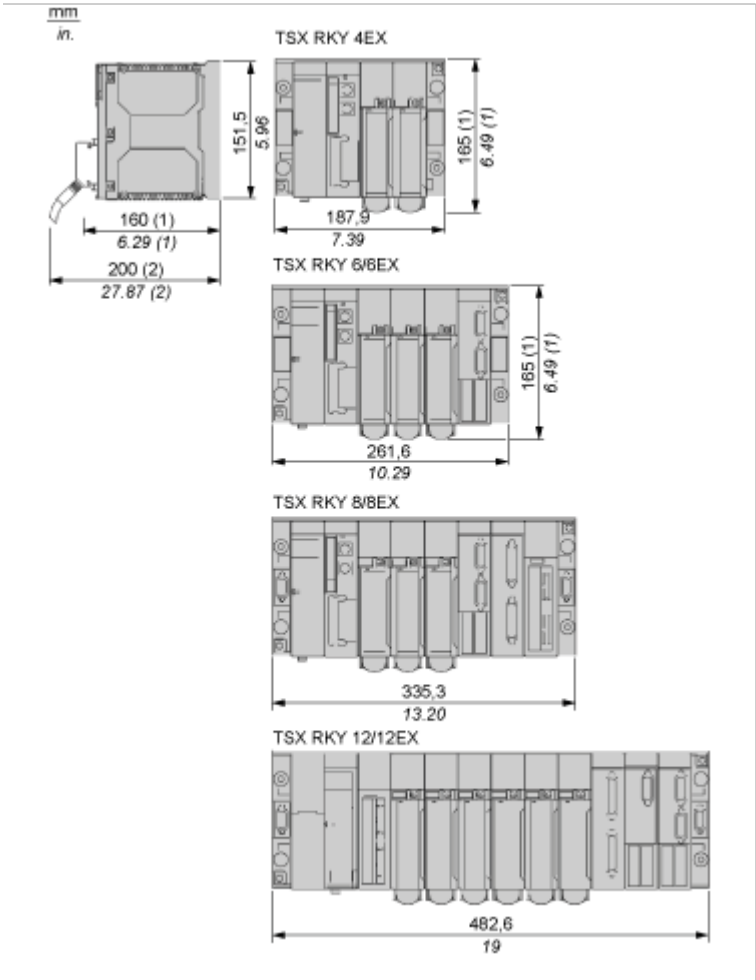

- (1) With screw terminal block modules.
(2) Maximum depth for all types of modules and their associated connectors.