

Product data sheet

Specifications



EtherNet TCP/IP module, Modicon Premium, Modbus TCP, UNI-TELWAY, 360mA at 5VDC, 10Mbit/s

TSXETY4103

! Discontinued - Service only

! Discontinued on: Dec 2, 2020

! To be end-of-service on: Dec 31, 2026

Product availability: Non-Stock - Not normally stocked in distribution facility

Main

Range Of Product	Modicon Premium Automation platform
Product Or Component Type	Ethernet TCP/IP module
Physical Interface	RJ45 - 10BASE-T/100BASE-TX 1 twisted pair
Transmission Rate	10/100 Mbit/s
Communication Service	Bandwidth management FDR server Global Data I/O scanning Modbus TCP messaging SMTP e-mail notification SNMP agent Uni-TE messaging
Supply	Via the power supply of the rack
Local Signalling	for collision detection (COL) 1 LED for Ethernet network status (RUN) 1 LED for Ethernet port fault (ERR) 1 LED for transmission/reception activity (TX/TR) 1 LED

Complementary

Communication Port Protocol	Modbus TCP Uni-Telway
Maximum Number Of Connections	64
Web Server	Transparent ready class B30
Web Feature	Rack viewer Data Editor (via PC terminal)
Marking	CE
Product Compatibility	PL7 Pro Unity Pro
Current Consumption	360 mA 5 V DC
Module Format	Standard
Net Weight	0.75 lb(US) (0.34 kg)

Environment

Price is "List Price" and may be subject to a trade discount – check with your local distributor or retailer for actual price.

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Standards	CSA 1010-1 FM Class 1 Division 2 group A FM Class 1 Division 2 group C FM Class 1 Division 2 group B FM Class 1 Division 2 group D EN 61131-2 UL 508
Ip Degree Of Protection	IP20
Ambient Air Temperature For Operation	32...140 °F (0...60 °C)
Relative Humidity	10...95 % 140 °F (60 °C) without condensation

Ordering and shipping details

Category	US1PC2222558
Discount Schedule	PC22
Gtin	3595863767650
Returnability	No
Country Of Origin	US

Packing Units

Unit Type Of Package 1	PCE
Number Of Units In Package 1	1
Package 1 Height	2.17 in (5.5 cm)
Package 1 Width	7.09 in (18.0 cm)
Package 1 Length	10.24 in (26.0 cm)
Package 1 Weight	15.03 oz (426.0 g)
Unit Type Of Package 2	S04
Number Of Units In Package 2	12
Package 2 Height	11.81 in (30.0 cm)
Package 2 Width	15.75 in (40.0 cm)
Package 2 Length	23.62 in (60.0 cm)
Package 2 Weight	13.21 lb(US) (5.991 kg)


Contractual warranty

Warranty	18 months
----------	-----------

Dimensions Drawings

Standard and Extendable Racks for Modules Mounting

Dimensions of Modules and Racks

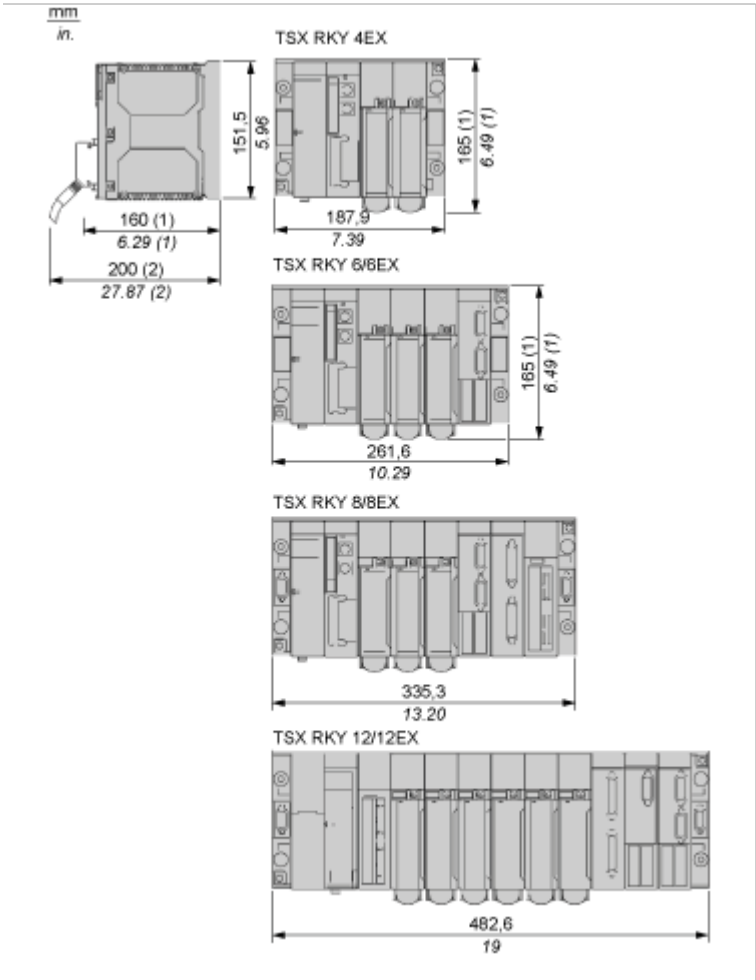

- (1) With screw terminal block modules.
- (2) Maximum depth for all types of modules and their associated connectors.